

PLUG MATES 4300


Rewireable - North America **Replaced by 4795/4796**



4300.0922 replaced by 4796.0000

NEW

20 Amp

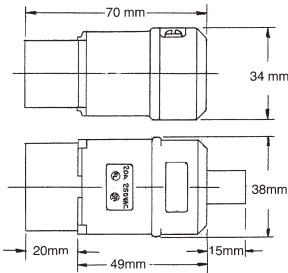


4300.0922 (mates with C19 outlet)

- For "cold" connections 70°C, Protection Class I
- AC inlet plug for high currents, with straight cable entry
- For North American cordage 16/3 SJ to 12/3 SJ (.325 to .475" dia.), or International (HAR Cord) 3x1.5mm² to 3x2.5mm² (8 to 12mm dia.)
- Disassemble plug for cable connection
- Housing: thermoplastic; prongs and terminals: brass
- For mating ac outlet see 6653, page 18

UL	listing	20A/250V	File # E96454
CSA	certification	20A/250V	File #LR702825
TUV	pending		



4300.0921 replaced by 4795.0000

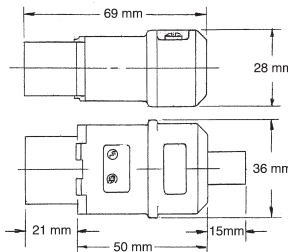

4300.0921 (mates with C20 inlet)

- For "cold" connections 65°C, Protection Class I
- AC outlet plug for high currents, with straight cable entry
- For North American cordage 16/3 SJ to 12/3 SJ (.275 to .475" dia.), or International (HAR Cord) 3x1.5mm² to 3x2.5mm² (8 to 12mm dia.)
- Disassemble plug for cable connection
- Housing: thermoplastic; prongs and terminals: brass
- For mating ac inlet/filter see C20F, page 53
- For mating ac inlet see 6153, page 18

UL	listing	20A/250V	File # E96454
CSA	certification	20A/250V	File #LR702825
TUV	pending		



Standards: IEC 320/C19 (outlet), /C20 (inlet)

CORDSETS



NEW


20 Amp



0888.0220/0222

NEW

Medical

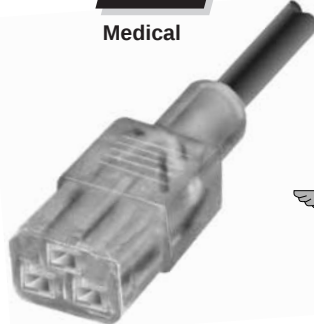

0888.0221

- PVC plastic molding, SJT cordage
- Medical caution labels available on request
- For mating ac inlet/filter see C20F, page 53.
- For mating ac inlet see 6153, page 18

0888.0220 (mates with C20 inlet)

- North American cordset, with Nema 5-15P plug end
- SJT cordage (3x14 AWG), black, 8 foot length

UL	listing	15A/125V *	File #E191239
CSA	certification	15A/125V *	File #LR702497 * Nema 5-15P max. rating

0888.0221 Medical Grade (mates with C20 inlet)

- Medical grade, North American cordset with Nema 5-15P plug end
- SJT cordage (3x14 AWG), grey cord, 10 foot length
- Transparent connector and plug ends, with "green dot" marking

UL	listing	15A/125V *	File #E147323
CSA	certification	15A/125V *	File #LR77840 * Nema 5-15P max. rating

0888.0222 (mates with C20 inlet)

- North American cordset, with Nema 6-20P plug end
- SJT cordage (3x12 AWG), black, 8' 2" length

c-UL listing, 20A/ 250V, File #E147323



Standards:
IEC 320/C19
(outlet end)



Standards:
Nema 5-15P
(plug end)




Standards:
Nema 6-20P
(plug end)

CORD RETAINING CLAMP

prevents loosening or accidental removal of plug





NEW

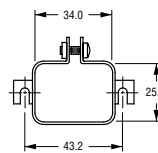

0888.0019

For rewireable plug mate 4300.0921

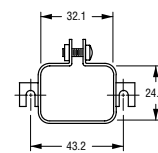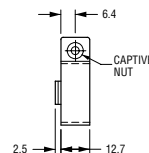

0888.0020

For cordsets shown above