
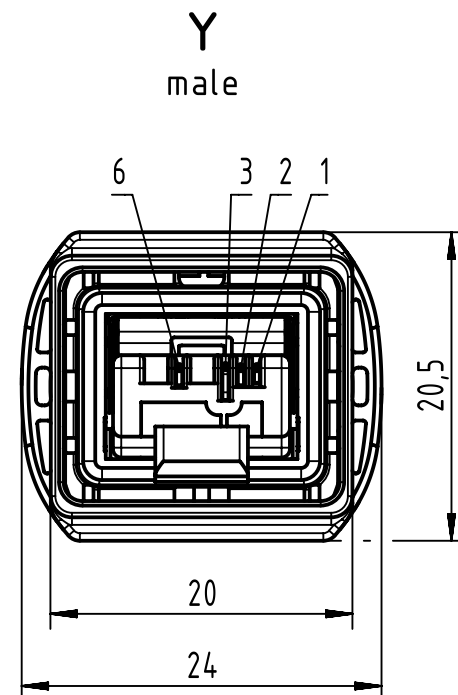
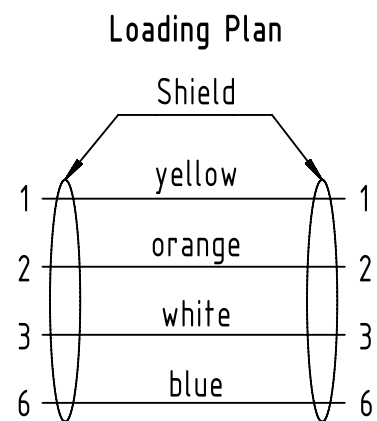
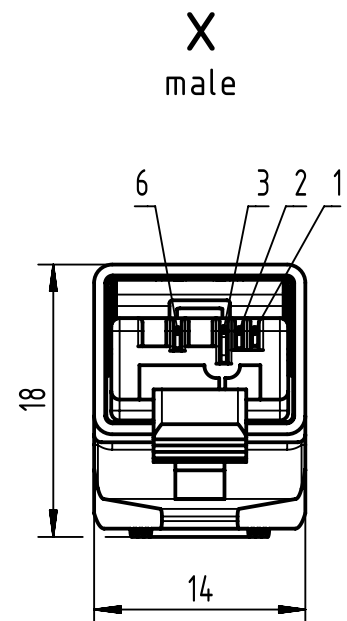
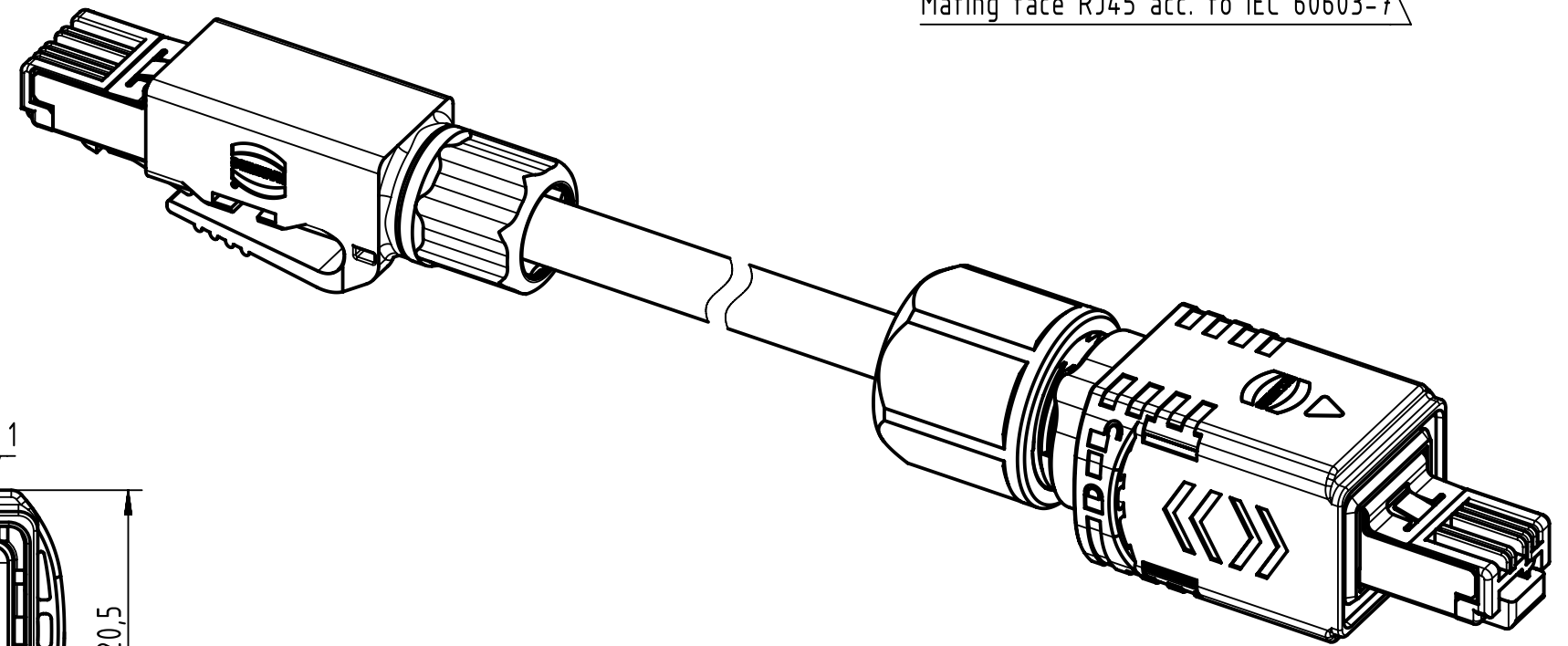


1	2
---	---

7	8
---	---

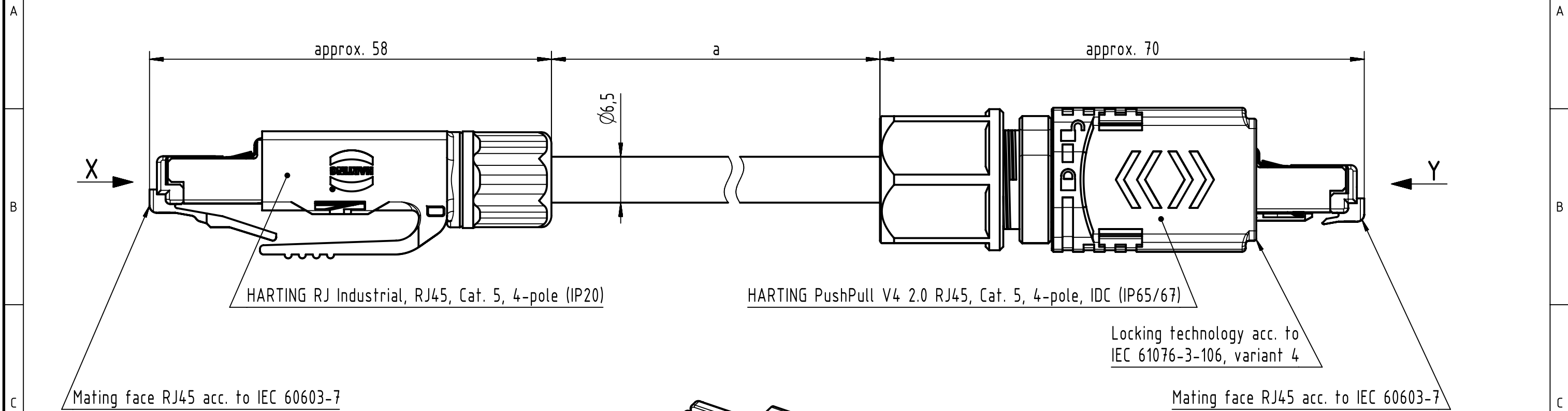

- Temperature range: -40°C ... $+70^{\circ}\text{C}$

 All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
 All rights reserved Department HCS - RO		Created by STOCHECIC Stoheci	Inspected by COSTEA Costea	Standardisation MUNTEANV Muntean	Date 2019-10-30	State Final Release	
HARTING Customised Solutions D-32339 Espelkamp		Title RJ45 IP20 - PPv4, 4xAWG22					Doc-Key / ECM-Nr. 100155407/UGD/024/F 500000159777
		Type TB	Number 0945701XXXX			Rev. F	Page 1/2

1				2				3				4				5				6				7				8			
A																				RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC, Cat. 5+, green				A							
B																				RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC outdoor, Cat. 5+, black				B							
C																				RJl Ethernet Standard Cable, 4xAWG 22/1, PVC, Cat. 5+, green				C							
D																				RJl Ethernet Standard Cable, 4xAWG 22/1, PVC, Cat. 5+, green				D							
E																				RJl Ethernet Standard Cable, 4xAWG 22/1, PVC, Cat. 5+, green				E							
F																				RJl Ethernet Standard Cable, 4xAWG 22/1, PVC, Cat. 5+, green				F							
44				09457010083				RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC outdoor, Cat. 5+, black				100								100											
43				09457010082								90				90															
42				09457010081								80				80															
41				09457010080								70				70															
40				09457010079								60				60															
39				09457010078								50				50															
38				09457010077								40				40															
37				09457010076								30				30															
36				09457010075								20				20															
35				09457010074								15				15															
34				09457010073								10				10															
33				09457010072								9				9															
32				09457010071								8				8															
31				09457010070								7				7															
30				09457010069								6				6															
29				09457010068								5				5															
28				09457010067								4				4															
27				09457010066								3				3															
26				09457010065								2				2															
25				09457010064								1.5				1.5															
24				09457010063								1				1															
23				09457010062								0.5				0.5															
22				09457010061								100				100															
21				09457010060								90				90															
20				09457010059				80				80																			
19				09457010058				70				70																			
18				09457010057				60				60																			
17				09457010056				50				50																			
16				09457010055				40				40																			
15				09457010054				30				30																			
14				09457010053				20				20																			
13				09457010052				15				15																			
12				09457010051				10				10																			
11				09457010031				9				9																			
10				09457010030				8				8																			
9				09457010029				7				7																			
8				09457010028				6				6																			
7				09457010027				5				5																			
6				09457010026				4				4																			
5				09457010025				3				3																			
4				09457010024				2				2																			
3				09457010023				1.5				1.5																			
2				09457010022				1				1																			
1				09457010021				0.5				0.5																			
Cont. no.				Part no.				Type of cable				Dim. a[m]																			
1				2				3				4				5				6				7				8			

88	09457011183	RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC, Cat. 5+, green				100							
87	09457011182					90							
86	09457011181					80							
85	09457011180					70							
84	09457011179					60							
83	09457011178					50							
82	09457011177					40							
81	09457011176					30							
80	09457011175					20							
79	09457011174					15							
78	09457011173					10							
77	09457011172					9							
76	09457011171					8							
75	09457011170					7							
74	09457011169					6							
73	09457011168					5							
72	09457011167					4							
71	09457011166					3							
70	09457011165					2							
69	09457011164					1.5							
68	09457011163					1							
67	09457011162					0.5							
66	09457011161					100							
65	09457011160					90							
64	09457011159	80											
63	09457011158	70											
62	09457011157	60											
61	09457011156	50											
60	09457011155	40											
59	09457011154	30											
58	09457011153	20											
57	09457011152	15											
56	09457011151	10											
55	09457011131	9											
54	09457011130	8											
53	09457011129	7											
52	09457011128	6											
51	09457011127	5											
50	09457011126	4											
49	09457011125	3											
48	09457011124	2											
47	09457011123	1.5											
46	09457011122	1											
45	09457011121	0.5											
Cont. no.	Part no.	Type of cable				Dim. a[m]							
		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing					
		All rights reserved Department HCS - RO		Created by STOCHECIC Stocheici		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean		Date 2019-10-30		State Final Release	
HARTING Customised Solutions D-32339 Espelkamp		Title RJ45 IP20 - PPv4, 4xAWG22		Doc-Key / ECM-Nr. 100155407/UGD/024/F 500000159777		Rev. F		Page 2/2					