


Part Number : [150320635](#)

Product Description : 0.30mm Pitch Premo-Flex FFC Jumper with Latching Ears, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 35 Circuits

Series Number : 15032

Status : Active

Product Category : Flat-Flexible Cable (FFC)

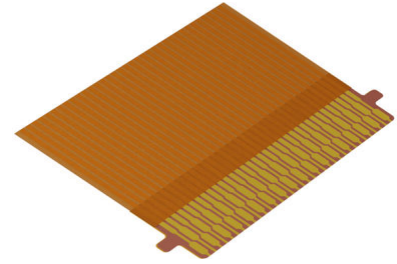

Documents and Resources

Drawings

[150320635 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[150320001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15032
Description	0.30mm Pitch Premo-Flex FFC Jumper with Latching Ears, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 35 Circuits
Product Name	Premo-Flex FFC Jumper
UPC	195842789586

Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	N/A

Physical

Cable Length	152.00mm
Circuits (Loaded)	35
Contact Layout Type	A (same side)
Design Feature	Miniaturization, Superior Retention
Material - Plating Mating	Gold
Net Weight	0.280/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm

Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FPC Connector, 0.30mm Pitch, Right-Angle, Bottom Contact, 0.95mm Height, 35 Circuits, Gold over Nickel Plating	<u>5035663502</u>

This document was generated on Jan 04, 2026