


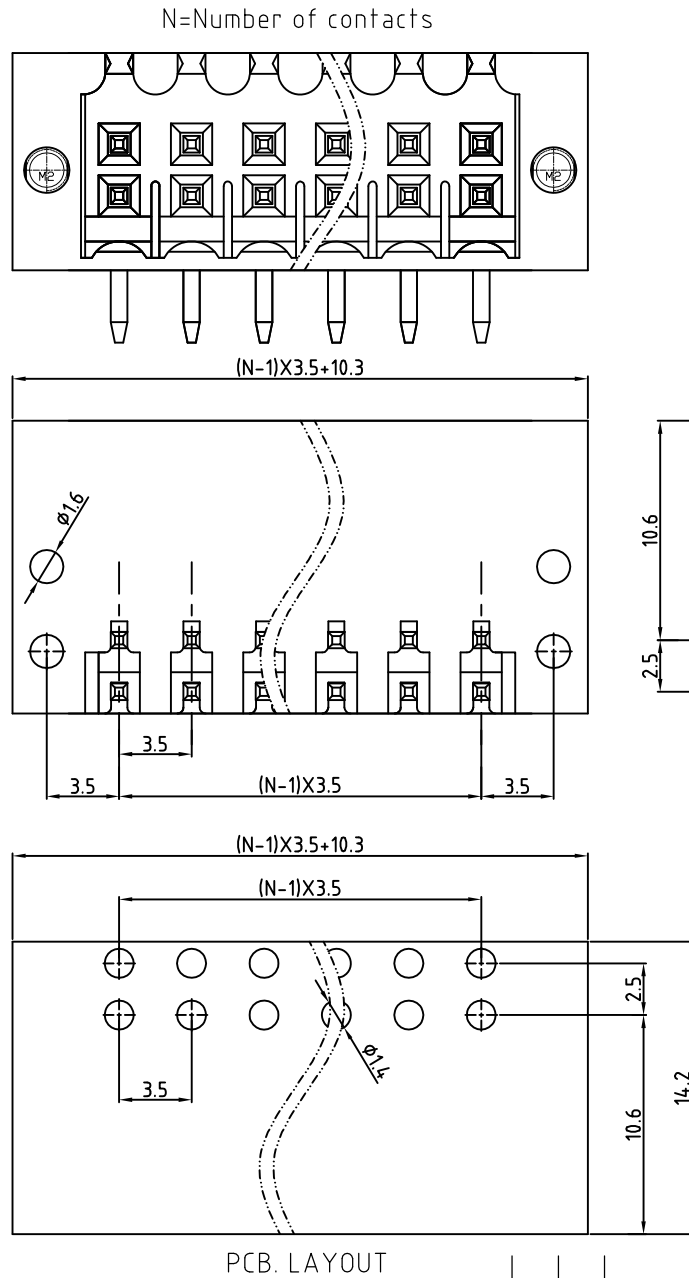

Technical Data:

Electrical

Pitch: 3.5mm

Voltage rating: 300V

Current rating: 12 Amps

Withstanding Voltage: 2500VAC(1min)

Mechanical:

Operating temperature: -40°C to +105°C

Soldering temperature

Temperature= 250°C±10°C /5 seconds max

Safety approval:

RoHS Compliance

Part No.:

OSTVXXX1201

No. of Poles

02 2 Poles

03 3 Poles

... ..

24 24 Poles

COLOR

0: Black (Standard)

2: Red

3: Orange

4: Yellow

5: Green

6: Blue

8: Grey

Nonstandard colors

Mins could apply

4	Flange nut	Copper Alloy	Tin plated	2
3	short Pin	Copper Alloy	Tin plated	1xN
2	Long Pin	Copper Alloy	Tin plated	1xN
1	Body	PA66-30%GF UL94V		1
ITEM	NAME OF PART	MATERIAL	NOTES	Q"TY
DWG.	DATE	UNITS:	MM	SHEET: 1 OF 1
CHK.	DATE	SCALE:	NONE 4:1 (:)	REV.: A
APP.	DATE	TITLE:	OSTVX SERIES 3.5MM	X. ±0.50
			WITH FLANGE RIGHT ANGLE	X.XX ±0.30
		PART NO.	OSTVXXX1201	X° ±1°
		DWG NO.	OSTVXXX1201	

REV	SIGN	DESCRIPTION	CHK.	DATE

ON-SHORE TECHNOLOGY, INC.