

1412682

<https://www.phoenixcontact.com/us/products/1412682>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B16, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, lateral, 1x M40, height: 76 mm, cable gland: none, Standard

Your advantages

- Good shielding in the event of electromagnetic interference

Commercial data

Item number	1412682
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF56
Product key	BF7APB
Catalog page	Page 620 (C-2-2019)
GTIN	4055626059761
Weight per piece (including packing)	212 g
Weight per piece (excluding packing)	224.7 g
Customs tariff number	85389099
Country of origin	CN

HC-STA-B16-HHFS-1STM40-EL-AL - Housing



1412682

<https://www.phoenixcontact.com/us/products/1412682>

Technical data

 
Notes

General	For contact inserts HC-B16, BB32, D40, DD72, HS6, HV6, M, K
General	also available as a powder-coated or color version: 1373007 HC-STA-B16-HHFS-1STM40-EL/...

Product properties

Product type	Housing with locking latch
Housing type	Sleeve housing
Application	Standard
Type	B16
No. of cable outlets	1
Type of the screw connection	1x M40
Type	Tall design
Cable outlet	lateral
Pg screw connection	none

Dimensions

Dimensional drawing	
Width	44 mm
Height	76 mm
Length	93.5 mm

Internal dimensions

Length of internal thread	14 mm
---------------------------	-------

Material specifications

Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated

Mechanical properties

Mechanical data

Type of the screw connection	1x M40
Locking type	Pin

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
----------------------	------

HC-STA-B16-HHFS-1STM40-EL-AL - Housing



1412682

<https://www.phoenixcontact.com/us/products/1412682>

	IP67
Enclosure rating (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Impact strength	IK08
Ambient temperature (operation)	-40 °C ... 125 °C

HC-STA-B16-HHFS-1STM40-EL-AL - Housing


1412682

<https://www.phoenixcontact.com/us/products/1412682>



Drawings

Dimensional drawing

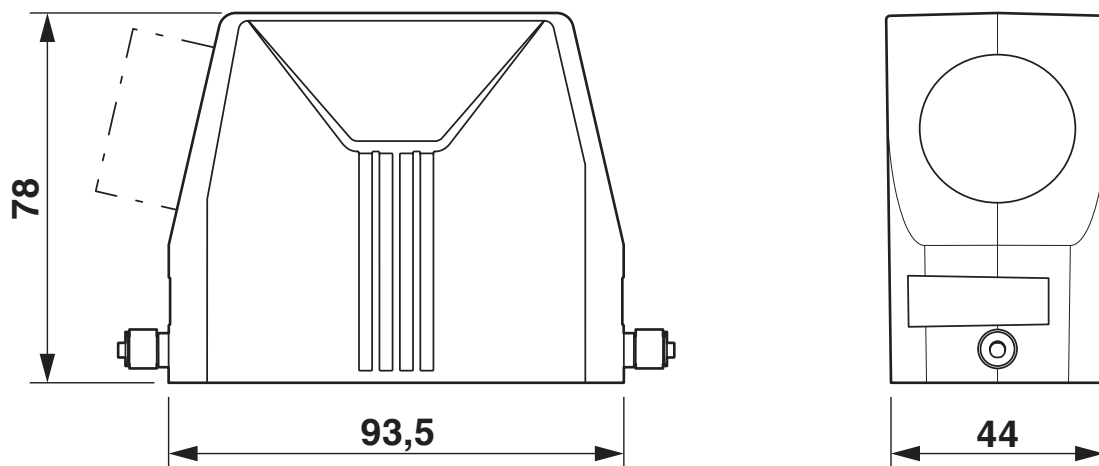

Dimensional drawing

HC-STA-B16-HHFS-1STM40-EL-AL - Housing



1412682

<https://www.phoenixcontact.com/us/products/1412682>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1412682>



DNV
Approval ID: TAE000037S



cUL Recognized
Approval ID: E255026



UL Recognized
Approval ID: E255026



EAC
Approval ID: RU C-DE.AI30.B.01102



EAC
Approval ID: RU C-DE.BL08.B.00511

cULus Recognized

HC-STA-B16-HHFS-1STM40-EL-AL - Housing



1412682

<https://www.phoenixcontact.com/us/products/1412682>

Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

HC-STA-B16-HHFS-1STM40-EL-AL - Housing



1412682

<https://www.phoenixcontact.com/us/products/1412682>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

HC-STA-B16-HHFS-1STM40-EL-AL - Housing



1412682

<https://www.phoenixcontact.com/us/products/1412682>

Accessories

G-INS-M40-M68N-NNES-S - Cable gland

1411167

<https://www.phoenixcontact.com/us/products/1411167>



Cable gland, material for screw connection: Brass, nickel-plated, application: Standard, external cable diameter 19 mm ... 28 mm, shielding: no, connecting thread: M40 x 1.5, color: silver, with O-ring

G-INSEC-M40-M68N-NCRS-S - Cable gland

1411192

<https://www.phoenixcontact.com/us/products/1411192>



Cable gland, material for screw connection: Brass, nickel-plated, application: EMC, external cable diameter 19 mm ... 27 mm, shielding: yes, connecting thread: M40 x 1.5, color: silver, with O-ring

HC-STA-B16-HHFS-1STM40-EL-AL - Housing

1412682

<https://www.phoenixcontact.com/us/products/1412682>



US-EMLP (20X9) CUS - Plastic label

0830085

<https://www.phoenixcontact.com/us/products/0830085>

Plastic label, can be ordered: by card, white, labeled according to customer specifications, mounting type: adhesive, lettering field size: 20 x 9 mm, Number of individual labels: 75



HC-B16-HCWS-PLR-BK - Protective cover

1346541

<https://www.phoenixcontact.com/us/products/1346541>

Protective cover B16, with single locking latch, protective cover material: PC, height: 26.3 mm, seal: yes



HC-STA-B16-HHFS-1STM40-EL-AL - Housing

1412682

<https://www.phoenixcontact.com/us/products/1412682>



US-EMLP-HA (20X9) - Plastic label

0830989

<https://www.phoenixcontact.com/us/products/0830989>



Plastic label, Card, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: adhesive, lettering field size: 20 x 9 mm, Number of individual labels: 70

WP-G HF IP66 M40 BK - Screw connection

3240901

<https://www.phoenixcontact.com/us/products/3240901>



Cable gland, metric thread, IP66 protection, straight

HC-STA-B16-HHFS-1STM40-EL-AL - Housing

1412682

<https://www.phoenixcontact.com/us/products/1412682>



WP-G HF IP69K M40 BK - Screw connection

3240887

<https://www.phoenixcontact.com/us/products/3240887>

Cable gland, metric thread, IP68/69k protection, straight



WP-GA HF IP66 M40 BK - Screw connection

3240929

<https://www.phoenixcontact.com/us/products/3240929>

Cable gland, metric thread, IP66 protection, angled



HC-STA-B16-HHFS-1STM40-EL-AL - Housing

1412682

<https://www.phoenixcontact.com/us/products/1412682>



WP-GA HF IP69K M40 BK - Screw connection

3240915

<https://www.phoenixcontact.com/us/products/3240915>

Cable gland, metric thread, IP68/69k protection, angled



WP-GR HF IP66 M40 BK - Screw connection

3240957

<https://www.phoenixcontact.com/us/products/3240957>

Cable gland, metric thread, IP66 protection, with strain relief



HC-STA-B16-HHFS-1STM40-EL-AL - Housing

1412682

<https://www.phoenixcontact.com/us/products/1412682>



WP-GR HF IP69K M40 BK - Screw connection

3240943

<https://www.phoenixcontact.com/us/products/3240943>



Cable gland, metric thread, IP68/69k protection, with strain relief

WP-G PP HF M40 - Screw connection

3241001

<https://www.phoenixcontact.com/us/products/3241001>



Cable gland made from PP with metric thread, IP65 protection

HC-STA-B16-HHFS-1STM40-EL-AL - Housing



1412682

<https://www.phoenixcontact.com/us/products/1412682>

WP-GT PP HF M40 - Screw connection

3241015

<https://www.phoenixcontact.com/us/products/3241015>

Cable gland made from PP with metric thread, rotatable, IP54 protection



WP-G BRASS IP40 M40 - Screw connection

3241050

<https://www.phoenixcontact.com/us/products/3241050>

Cable gland made from brass with metric thread, IP40 protection



HC-STA-B16-HHFS-1STM40-EL-AL - Housing



1412682

<https://www.phoenixcontact.com/us/products/1412682>

WP-GT BRASS M40 - Screw connection

3241036

<https://www.phoenixcontact.com/us/products/3241036>

Cable gland made from brass with metric thread, rotatable, IP40 protection



WP-G BRASS IP65 M40 - Screw connection

3241064

<https://www.phoenixcontact.com/us/products/3241064>

Cable gland made from brass with metric thread, IP65 protection



Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com