



Fittings for metallic conduits with liquid-tight cover

• LTS-EI End Insert

Nickel plated brass.

Features and Benefits

- Single part
- Caps end of conduit




HelaGuard LTS-EI End Insert.

MATERIAL	Nickel Plated Brass (NPB)
Operating Temperature	-100 °C to +300 °C

HF ✓

RoHS ✓

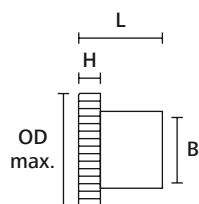

HelaGuard fitting, end insert

TYPE	Nominal Ø	Min. Bore Size (B)	Length (L)	Outside Ø max (OD max.)	Height (H)	Pack Cont.	Colour	Article-No.
LTS10-EI	10	5.6	16.3	13.8	3.6	10 pcs.	Metal (ML)	166-32700
LTS12-EI	12	8.6	16.3	16.1	3.6	10 pcs.	Metal (ML)	166-32701
LTS16-EI	16	10.7	16.5	20.0	4.5	10 pcs.	Metal (ML)	166-32702
LTS20-EI	20	14.5	17.0	22.9	4.5	10 pcs.	Metal (ML)	166-32703
LTS25-EI	25	18.0	21.5	28.7	6.1	10 pcs.	Metal (ML)	166-32704
LTS32-EI	32	24.6	24.0	35.0	6.6	2 pcs.	Metal (ML)	166-32705
LTS40-EI	40	32.7	28.0	45.0	8.1	1 pcs.	Metal (ML)	166-32706
LTS50-EI	50	37.7	30.0	51.0	8.1	1 pcs.	Metal (ML)	166-32707
LTS63-EI	63	49.0	35.0	63.0	10.1	1 pcs.	Metal (ML)	166-32708

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content.