


Specification Sheet

Part Number: 156-00507

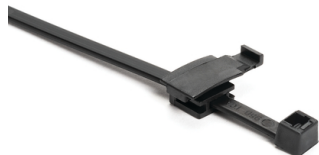

Head design contains clamping rails to provide full circumferential compression around bundles.

Bent tail allows for quick insertion into head.

Connector Clip with Cable Tie, 8.0" Long, PA66HS, Black, 100/pkg

Article Number 156-00507

Type T50RYCCA

Color Black (BK)

Quantity Per pack

Product Description Connector Clips feature various attachment point configurations to accommodate the many connectors on the market. They are first mated with a connector on a wire harness or cable assembly, then secured to a surface using the integrated mount. With so many configurations available, attachment surfaces can be a hole, edge, stud or even another harness assembly.

Short Description Connector Clip with Cable Tie, 8.0" Long, PA66HS, Black, 100/pkg

Global Part Name T50RYCCA-PA66HS/PA66HIRHS-BK

Minimum Tensile Strength (Imperial)	50
Minimum Tensile Strength (Metric)	225
Length L (Imperial)	8.0
Length L (Metric)	200.0
Identification Plate Position	none
Releasable Closure	No
Tie Closure	plastic pawl
Width W (Imperial)	0.18
Width W (Metric)	4.6
Bundle Diameter Min (Imperial)	0.06
Bundle Diameter Min (Metric)	1.52
Bundle Diameter Max (Imperial)	1.97
Bundle Diameter Max (Metric)	50.0
Thickness T (Metric)	1.2
Height H (Imperial)	0.3
Height H (Metric)	7.5

Material	Polyamide 6.6 heat stabilized (PA66HS) Polyamide 6.6, high impact modified, heat stabilized (PA66HIRHS)
Foot Part Material	PA66HIRHS
Material Shortcut	PA66HIRHS PA66HS
Flammability	UL 94 HB UL 94 V-2
UV Resistant (Yes/No)	No
Use Conditions	For Indoor and Outdoor Use
Operating Temperature	-40°F to +221°F (-40°C to +105°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	100
Package Quantity (Metric)	100
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

