


PMB/RMB

Metallized Polypropylene Film Capacitors


IGBT Direct Mount with Double-sided Electrodes




STYLE S, SM8, T, TM8

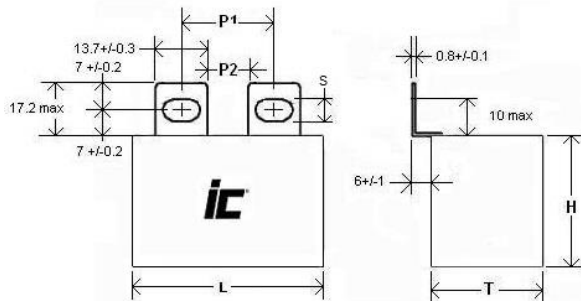


STYLE L

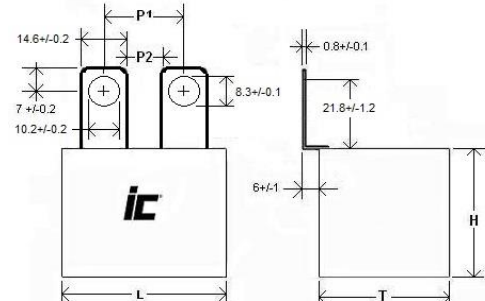


STYLE E

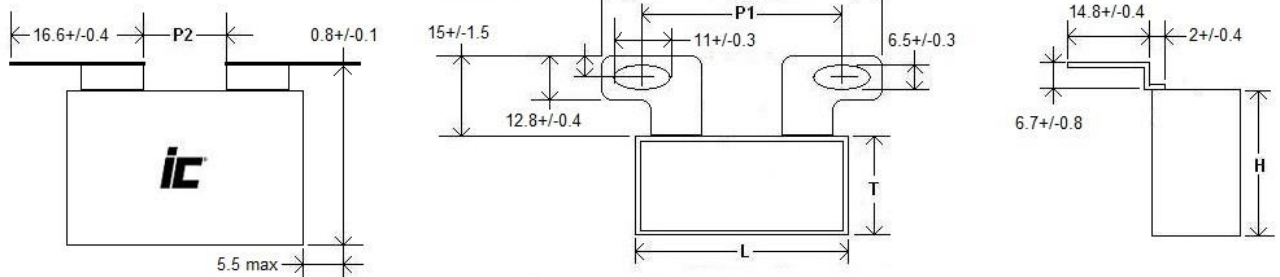

Style B

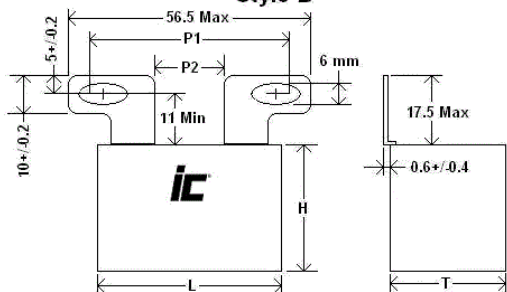

Style F, FM8, G, GM8

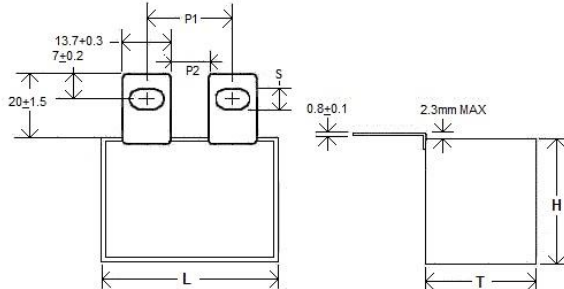

L=42.5mm, P1=23 to 28mm, P2=11mm MIN
 L=57.5mm, P1=37 to 42mm, P2=24mm MIN

Fixing pitch and distance between lugs (mm)

Lugs	L	P1	P2	S
S,V,F	42 - 42.5	23 - 28	11	6
	57.5	37 - 42	24	6
SM8,VM8, FM8	42 - 42.5	25 - 26	11	8
	57.5	39 - 40	24	8
T,W,G	42 - 42.5	20 - 25	8	6
	57.5	34 - 39	21	6
TM8,WM8,GM8	42 - 42.5	22 - 23	8	8
	57.5	36 - 37	21	8
N,P	57.5	23 - 28	11	6
NM8, PM8	57.5	25 - 26	11	8
A	40 - 42.5	53.5 - 63	----	8
	57.5	68.5 - 77	----	8
B	42 - 42.5	32 - 45	17	6
E	42 - 42.5	30 - 37	15	6
L	42 - 42.5	22 - 24	8	6
	57.5	36 - 38	21	8





PMB/RMB

Metallized Polypropylene Film Capacitors

IGBT Direct Mount with Double-sided Electrodes



--	--

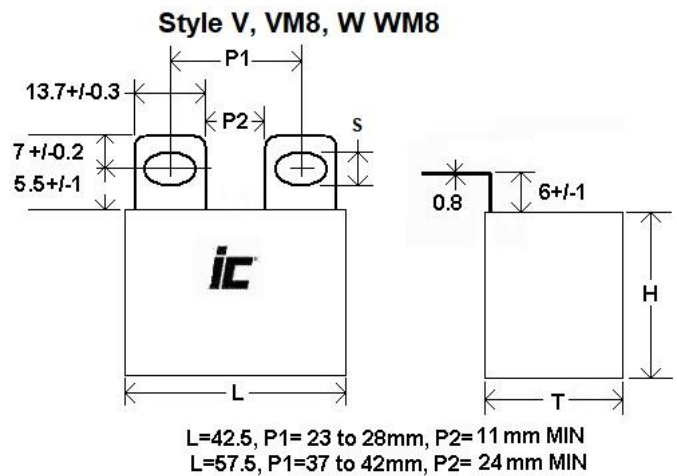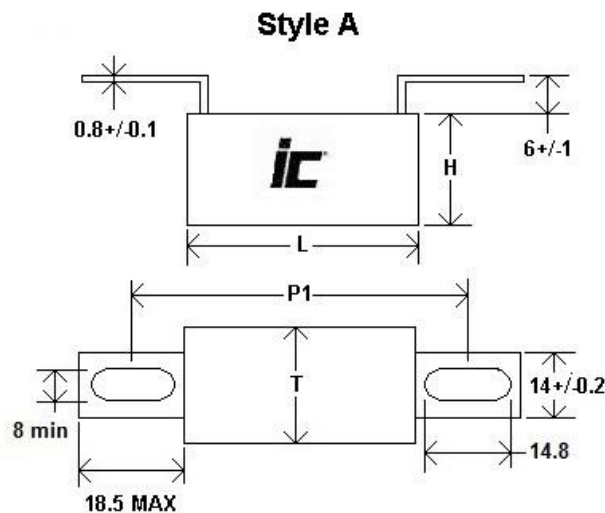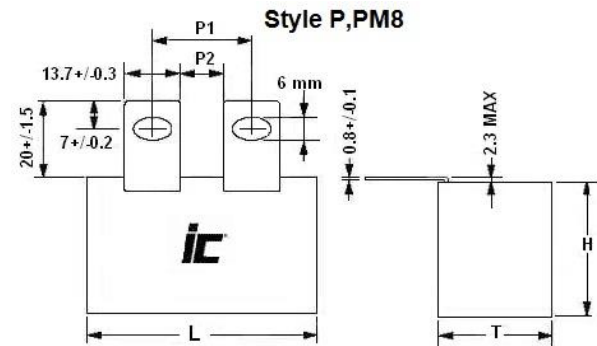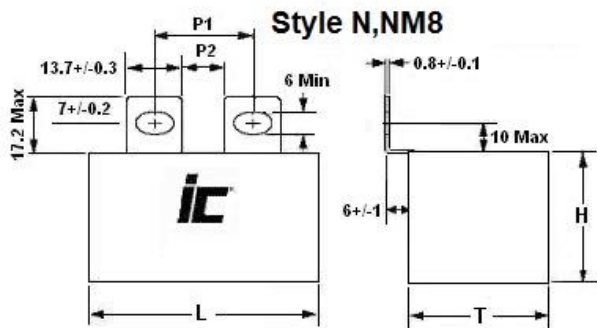

Americas / EU
 Phone: 1-508-996-8561
 Email: cdena@cde.com



**CORNELL
DUBILIER**



Asia
 Phone: 852-2793-0931
 Email: cdeasia@cde.com

Oct-21

PMB_RMB

Metallized Polypropylene,
Power Semiconductor Direct
Mount Snubber Lug terminals

WVDC	Capacitance (μF)	IC PART NUMBER	dv/dt (v/μ sec.)	Maximum RMS Ripple Current (A) 100 kHz, +70°C	Typical ESR (mΩ) 100 kHz, +25°C	Dims LxHxT (mm)
700	1	105PMB700K#	600	16.5	3.3	42.5x28x17
700	1.2	125PMB700K#P2	600	18	3.1	42.5x27.5x24.5
700	1.2	125PMB700KA#	600	18	3.1	42x32x17
700	1.5	155PMB700K#	600	20	2.8	42.5x33.5x22
700	1.5	155RMB700K#	455	13.5	4.7	42.5x28x17
700	2	205PMB700K#P1	600	23.5	2.5	42.5x35.5x33.5
700	2.2	225PMB700K#	600	24.5	2.4	42.5x35.5x33.5
700	2.2	225PMB700K#	600	24.5	2.4	42.5x35.5x33.5
700	2.2	225PMB700KA#	600	24.5	2.4	42.5x37x28
700	2.2	225RMB700K#	455	16.5	3.7	42.5x30x22
700	2.5	255PMB700K#P1	600	25.5	2.2	42.5x35.5x33.5
700	2.5	255RMB700K#	455	18	3.5	42.5x33.5x22
700	3	305PMB700K#P0	600	28.5	2.1	42.5x45x33
700	3	305PMB700KA#	600	28.5	2.1	42.5x45x30
700	3.3	335PMB700K#	600	28	2.1	42.5x45x33
700	3.3	335PMB700K#	600	29.5	2.1	42.5x45x33
700	3.3	335PMB700KA#	600	29.5	2.1	42.5x45x30
700	3.3	335RMB700K#	455	21	3.1	42.5x35.5x33.5
700	3.5	355PMB700K#P0	600	31.5	2	42.5x45x33
700	4	405PMB700K#	360	29	2.3	57.5x45x30
700	4	405RMB700K#	455	24	2.7	42.5x35.5x33.5
700	4.7	475PMB700K#	360	32.5	2.1	57.5x50x35
700	4.7	475RMB700K#	455	26.5	2.6	42.5x45x30
700	5	505PMB700K#	360	32	2.1	57.5x50x35
700	5	505PMB700K#	360	33	2.1	57.5x50x35
700	5	505RMB700K#	455	27.5	2.6	42.5x45x30
700	5.6	565PMB700K#	360	34	2	57.5x50x35
700	5.6	565RMB700K#	455	29.5	2.3	42.5x45x33
700	6.3	635PMB700K#	360	35.5	1.8	57.5x50x35
700	6.8	685PMB700K#	360	37.5	1.7	57.5x57.5x38
700	6.8	685RMB700K#	285	25	3.1	57.5x45x30
700	7.5	755RMB700K#	285	27		

PMB_RMB

**Metallized Polypropylene,
Power Semiconductor Direct
Mount Snubber Lug terminals**

WVDC	Capacitance (μF)	IC PART NUMBER	dv/dt (v/μ sec.)	Maximum RMS Ripple Current (A) 100 kHz, +70°C	Typical ESR (mΩ) 100 kHz, +25°C	Dims LxHxT (mm)
1200	2.5	255PMB122K#	575	34	2.1	57.5x50x35
1200	2.5	255RMB122K#	500	26	3.4	57.5x45x30
1200	3	305RMB122K#	500	28	3	57.5x50x35
1200	3.3	335PMB122K#	575	37.5	1.9	57.5x57.5x38
1200	3.3	335RMB122K#	500	29.5	2.9	57.5x50x35
1200	3.5	355PMB122K#	575	38.5	1.9	57.5x57.5x38
1200	4	405RMB122K#	500	31	2.5	57.5x57.5x38
1200	4.7	475RMB122K#	500	34	2.3	57.5x57.5x38
1500	0.22	224PMB152K#	1220	12	6.1	42.5x28x17
1500	0.33	334PMB152K#P2	1220	14	4.6	42.5x27.5x24.5
1500	0.33	334PMB152KA#	1220	14.5	4.6	42x32x17
1500	0.39	394PMB152K#	1000	11.6	6.6	42.5x28x17
1500	0.39	394PMB152K#P2	1220	16	4.2	42.5x27.5x24.5
1500	0.47	474PMB152K#P1	1220	18.5	3.7	42.5x35.5x33.5
1500	0.47	474PMB152KA#	1220	18.5	3.7	42.5x33.5x22
1500	0.47	474RMB152K#	1000	13.5	5.8	42x32x14
1500	0.56	564RMB152K#	1000	14.5	5.1	42.5x30x22
1500	0.56	564RMB152KA#	1000	14.5	5.1	42.5x27.5x24.5
1500	0.68	684PMB152K#P1	1220	21.5	3.1	42.5x35.5x33.5
1500	0.68	684PMB152KA#	1220	22	3.1	42.5x37x28
1500	0.68	684RMB152K#	1000	15.5	4.7	42.5x33.5x22
1500	0.75	754PMB152K#P1	1220	23	2.8	42.5x35.5x33.5
1500	1	105PMB152K#P0	1220	26.5	2.5	42.5x45x33
1500	1	105RMB152K#	1000	19.5	4	42.5x37x28
1500	1.2	125PMB152K#	870	26.5	2.8	57.5x45x30
1500	1.2	125RMB152K#	1200	23.5	3.5	42.5x45x30
1500	1.5	155PMB152K#	725	30	2.5	57.5x50x35
1500	1.5	155RMB152K#	1000	25.5	3.2	42.5x45x33
1500	1.8	185PMB152K#	725	32	2.3	57.5x50x35
1500	2	205RMB152K#	575	24.5	3.5	57.5x45x30
1500	2.2	225PMB152K#	725	34.		