
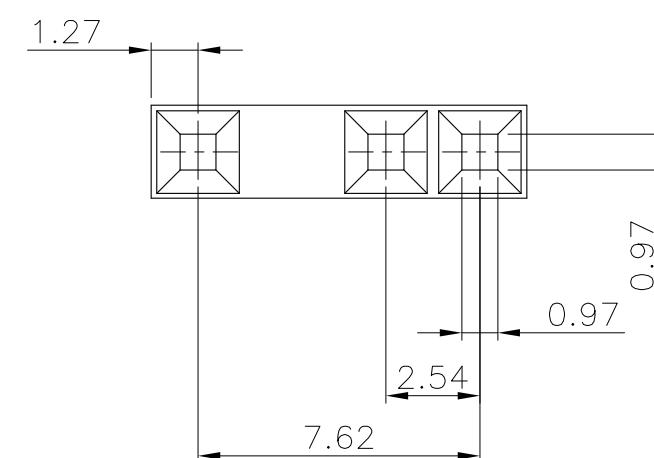
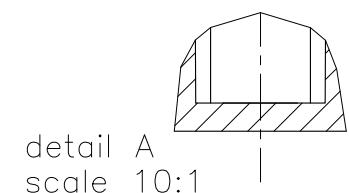
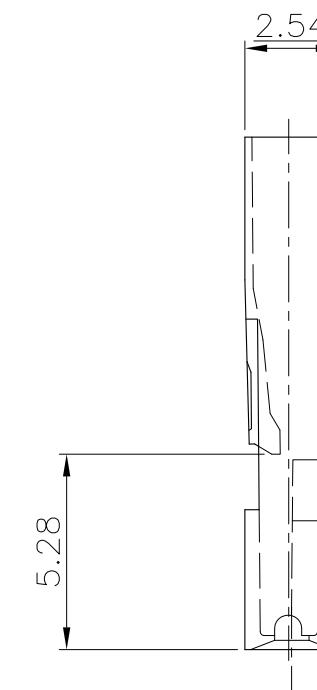


PRODUCT NUMBER

71627-001LF

"LF" INDICATES THE PRODUCT IS RoHS
COMPLIANT, SEE NOTE 5.

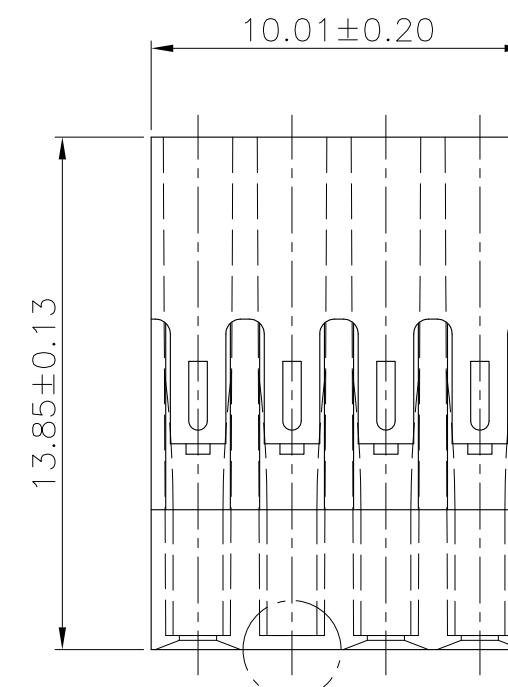

NOTES:

1. MATERIAL: POLYPHENYLENE OXYDE (NORYL) COLOR BLACK UL 94V-1
2. LATCH TERMINAL MUST WITHSTAND A MIN PULL-OUT FORCE OF 2.9 Kg
3. TERMINALS MUST BE CRIMPED PROPERLY FOR SATISFACTORY LATCHING
SEE TA-295 FOR CRIMPING INSTRUCTIONS.
4. THIS HOUSING IS INTENDED FOR USE WITH MINI PV TERMINAL WITH 22-36 GAUGE WIRE.
5. - RoHS COMPATIBLE PRODUCT SPECIFICATIONS
 - a - LABELING:
 - MEETS PACKAGING SPECS AS PER GS-14-920
 - b - LEGAL STATEMENT: SEE GS-22-008

THE PRODUCT IS NOT INTENDED TO BE EXPOSED TO A
MANUFACTURING SOLDER PROCESS.

| mat'l. code 16-502-001 | | | | surface ISO 1302 | tolerance ISO 406 ISO 1101 | projection | product family BERGCON |
|---------------------------|----------|----------------|----------|---------------------------------------|-------------------------------|------------------------------------|--|
| ltr | ecn no | dr | date | tolerances unless otherwise specified | | | title MINI-LATCH POLARIZED S.R.HOUSING |
| A | H88078 | CVE | 89.01.12 | angles | linear | .X ±0.3 .XX ±0.15 .XXX ±0.05 | |
| B | F00405 | VIB | 00.05.16 | | | | |
| C | F05-0235 | DLE | 05.08.25 | ±2° | | | scale 1:1 |
| D | F05-0286 | DLE | 05.11.07 | dr | D LEGRAN | 05.08.18 | dwg no 71627 |
| E | F06-0218 | DLE | 06.07.11 | engr | P NIZZI | 05.08.18 | |
| F | F07-0226 | LMU | 07.06.26 | chr | P NIZZI | 05.08.18 | |
| G | B-14321 | LMU | 13.03.21 | appd | P NZ | 05.08.18 | |
| sheet index | | revision sheet | | | | | |

