


Product mass

Precautions for use

General notes

SA-2020-V

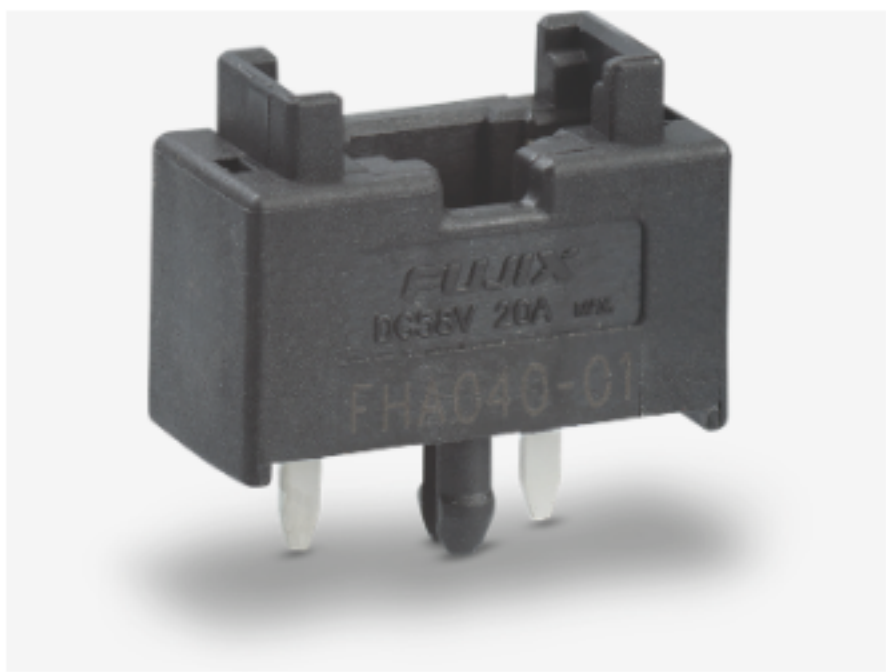

Compact design


Automotive blade fuse

Order model number


Order model numberSA-2020-V

- Basic information
- Dimension
- Soldering heat resistance conditions
- Optional
- Conformity product / Mate product
- Download

Printed circuit board mounting image

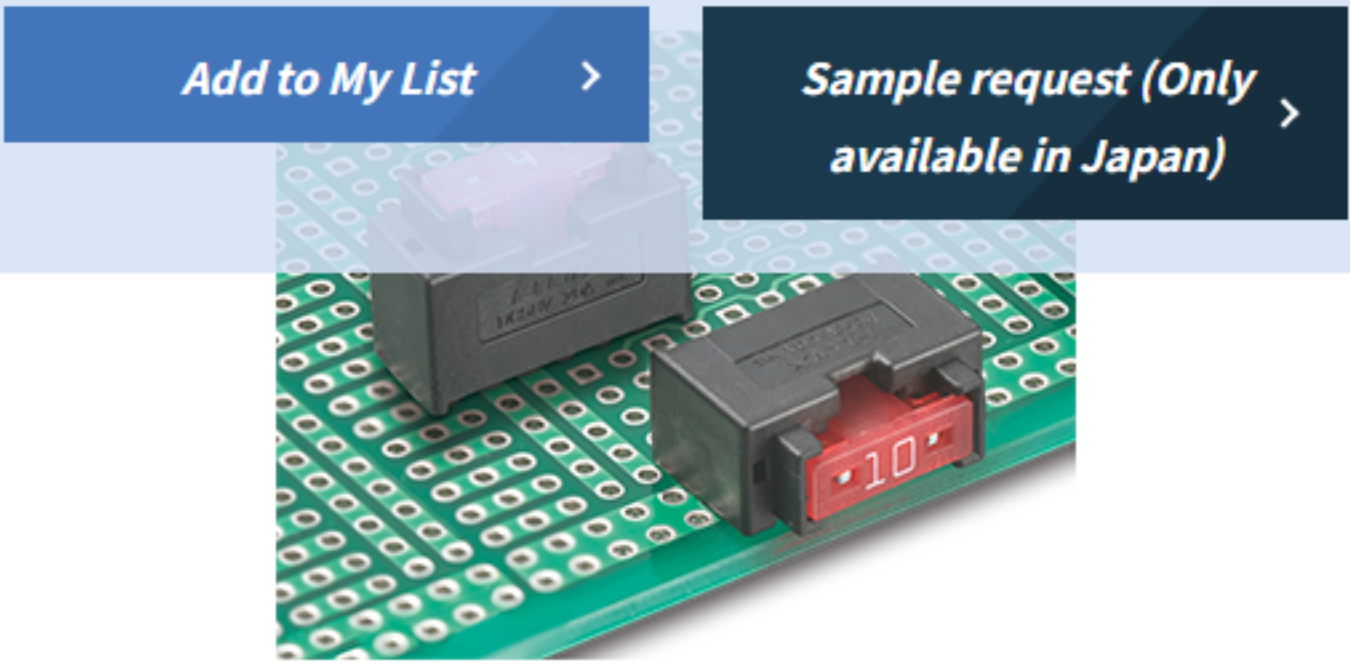

Fuse Puller

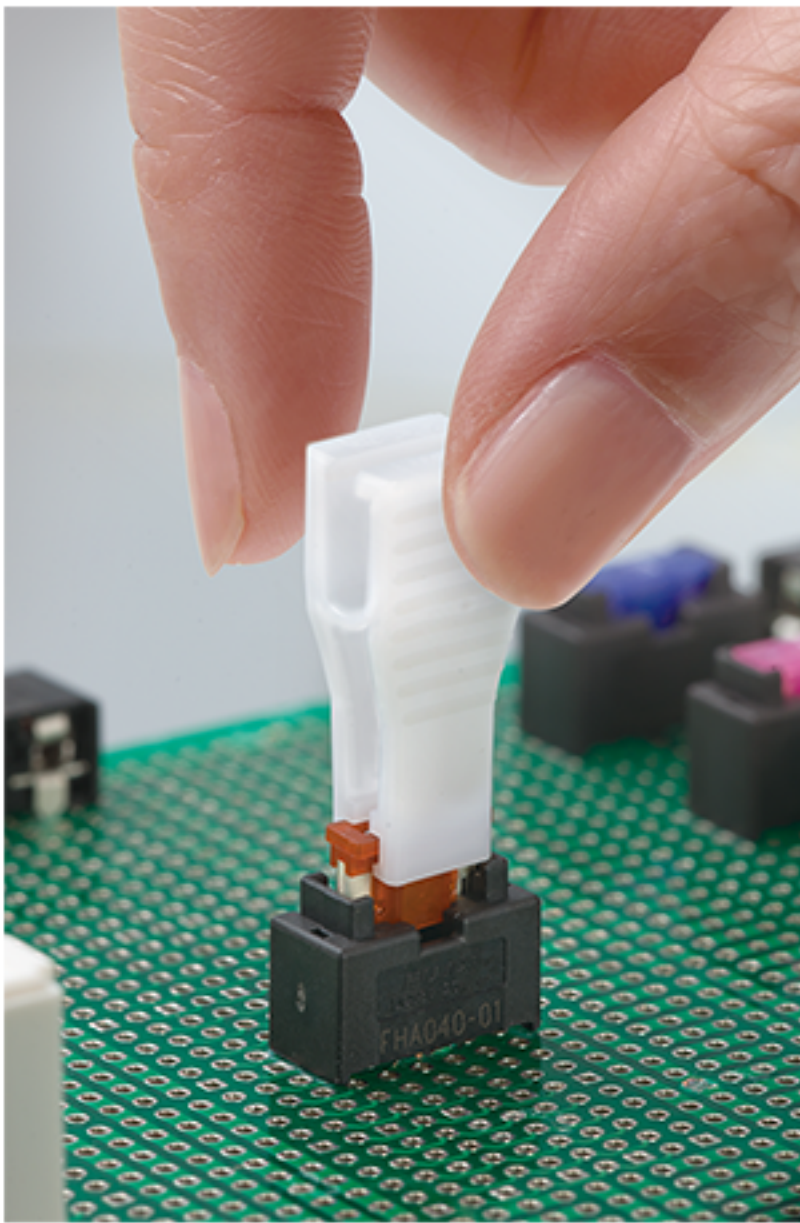

Mating fuse

Low profile blade fuse

Basic information

Rating	AC/DC58V-20A
Insulation resistance	DC500V、1000MΩ Min
Withstand voltage	AC600V (1minute)
Main insulator	Nylon66
Mate fuse	Low profile blade fuse
Terminal type	PC terminal
Body color	B (Black)
PCB thickness	1.6mm