

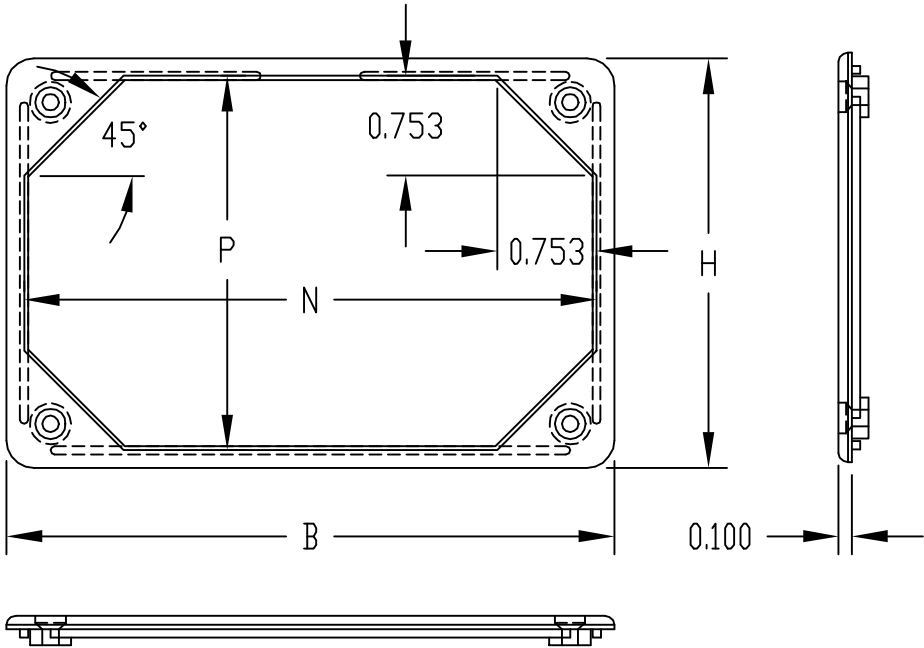


|           |                    |          |                                                                                                                    |           |        |
|-----------|--------------------|----------|--------------------------------------------------------------------------------------------------------------------|-----------|--------|
| PART NAME | UTILIBOX (STYLE A) | PART No. | CU-3281 thru CU-3284 and CU-3287<br>CUR-3281 thru CUR-3284 and CUR-3287<br>CUR-3281-C thru CUR-3284-C & CUR-3287-C | REV. DATE | 9-2-10 |
|-----------|--------------------|----------|--------------------------------------------------------------------------------------------------------------------|-----------|--------|


MATERIAL:  
 BODY AND STANDARD COVERS  
 ABS THERMOPLASTIC (FLAMMABILITY RATING UL94-5VA)  
 RECESSED COVERS (CUR-)  
 ABS THERMOPLASTIC (FLAMMABILITY RATING UL94V-0)  
 CLEAR COVERS (-C)  
 ABS THERMOPLASTIC (FLAMMABILITY RATING UL94V-2)  
 FINISH  
 BODY AND STANDARD COVERS ARE BLACK TEXTURED  
 RECESSED (CUR-) AND CLEAR COVERS (-C) ARE SMOOTH FINISH

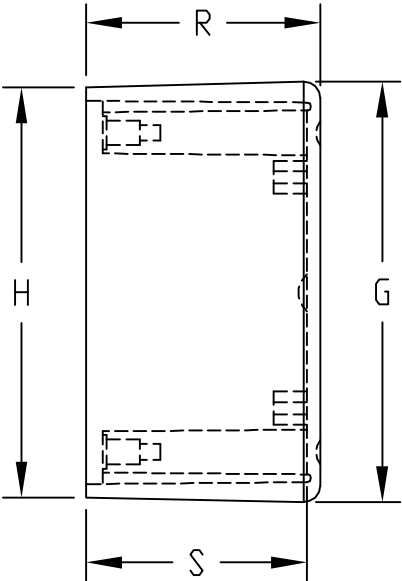

FOUR (4) #4-40 x 0.375" LG. SCREWS  
 SUPPLIED FOR ASSEMBLING COVER  
 TO BODY  
 MOUNTING BOSSSES USE EITHER M2.5  
 METRIC OR #4 STD. SHEET METAL  
 SCREWS x 0.250" LG.  
 (NOT SUPPLIED)

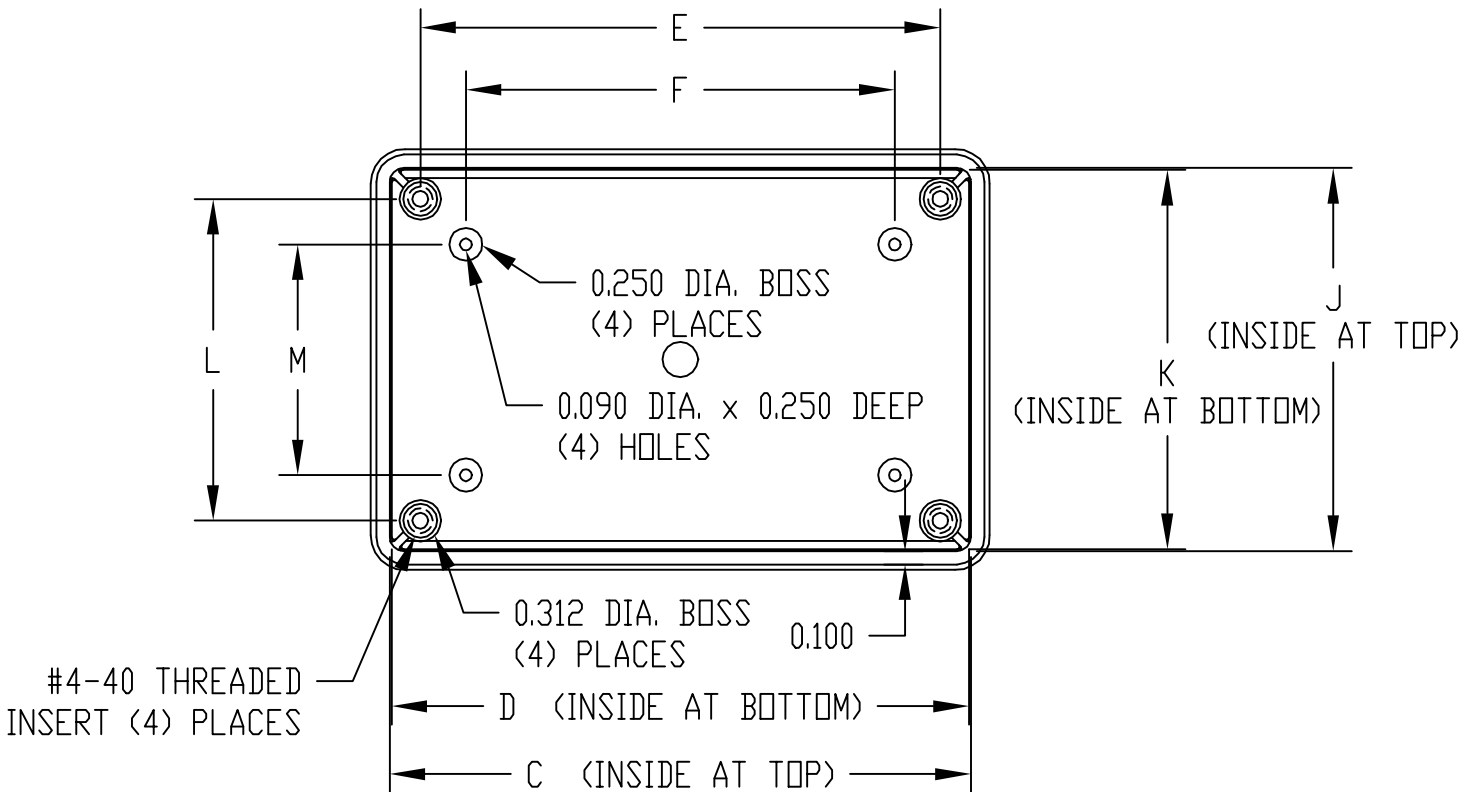

NOTE: ALL DIMENSIONS HAVE ±0.010 TOLERANCE  
 UNLESS OTHERWISE SPECIFIED

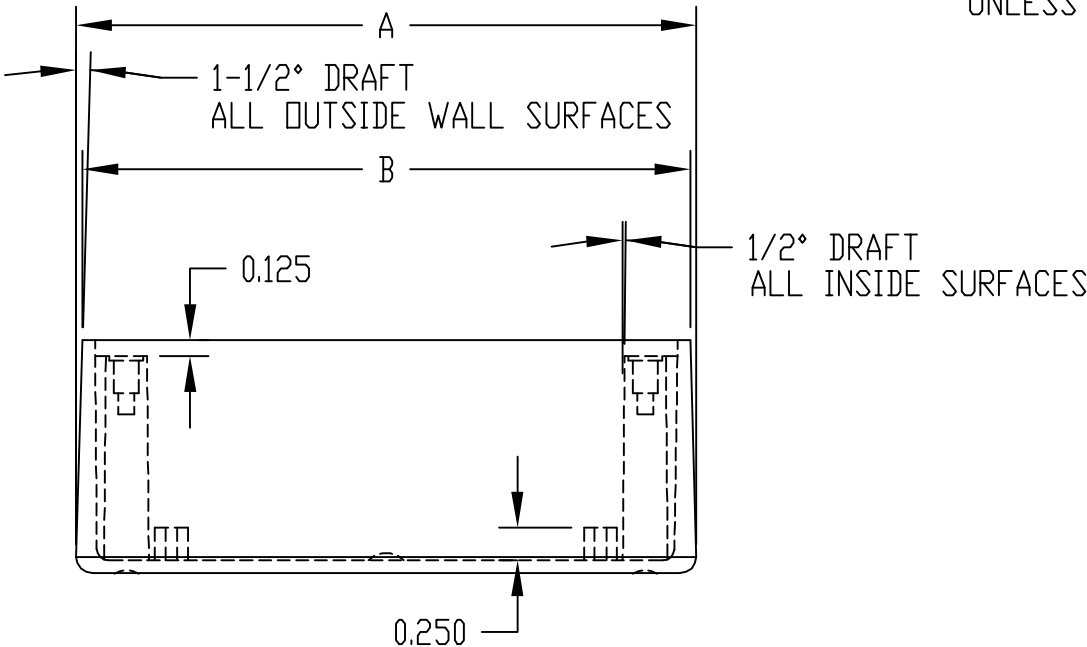

| PART No. | A     | B     | C     | D     | E     | F     | G     | H     | J     | K     | L     | M     | N     | P     | R     | S     |
|----------|-------|-------|-------|-------|-------|-------|-------|-------|-------|-------|-------|-------|-------|-------|-------|-------|
| CU-3281  | 4.690 | 4.604 | 4.404 | 4.375 | 3.938 | 3.250 | 3.190 | 3.104 | 2.904 | 2.875 | 2.438 | 1.750 | 4.337 | 2.837 | 1.772 | 1.672 |
| CU-3282  | 4.724 | 4.612 | 4.412 | 4.375 | 3.938 | 3.250 | 4.724 | 4.612 | 4.412 | 4.375 | 3.938 | 3.250 | 4.345 | 4.345 | 2.256 | 2.156 |
| CU-3283  | 6.224 | 6.112 | 5.912 | 5.875 | 5.438 | 4.750 | 4.724 | 4.612 | 4.412 | 4.375 | 3.938 | 3.250 | 5.845 | 4.345 | 2.256 | 2.156 |
| CU-3284  | 7.724 | 7.612 | 7.412 | 7.375 | 6.938 | 6.250 | 4.724 | 4.612 | 4.412 | 4.375 | 3.938 | 3.250 | 7.345 | 4.345 | 2.256 | 2.156 |
| CU-3287  | 6.224 | 6.112 | 5.912 | 5.875 | 5.438 | 4.750 | 4.724 | 4.612 | 4.412 | 4.375 | 3.938 | 3.250 | 5.845 | 4.345 | 1.250 | 1.156 |