


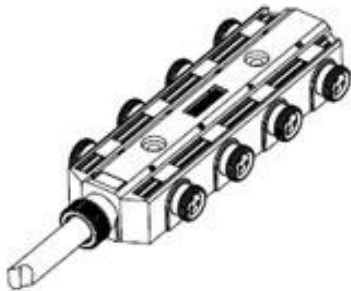

Part Number : [1300600022](#)
Product Description : Mini-Change MPIS, 3 Pole
Female, 6 Ports with Molded Cable 0.92m Length
Series Number : 130060
Status : Active
Product Category : Passive Distribution Boxes
Engineering Number : 409P893-03



Documents & Resources

Drawings

[1300600022 sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)4165-DC (25 June 2025)
EU RoHS	Not Reviewed per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Active
Category	Passive Distribution Boxes
Series	130060
Description	Mini-Change MPIS, 3 Pole Female, 6 Ports with Molded Cable 0.92m Length
IP Rating	IP67
NEMA Rating	NEMA 6
Product Name	Mini-Change
UPC	78678861898

Agency

CSA	LR6837
-----	--------

Electrical

Current - Maximum per Contact	7.0A
Functional Wiring	Parallel
Voltage - Maximum	600V AC/DC
Wiring Configuration	Single I/O per Port

Physical

Bus I/O	Mini-Change
Cable Connector Orientation	Straight
Cable Length	0.91m
Home Run Cable Length	0.92m
Home Run Connector	N/A
Home Run Interface	N/A
Keyway	Single
LED Indicator	None
Material - Cable Jacket	PVC

Material - Housing	PBT
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Net Weight	1.000/g
Orientation	Side Mount
Poles	3
Poles (wired)	3
Ports	8
Temperature Range - Operating	-25°C to +90°C

This document was generated on Sep 17, 2025