
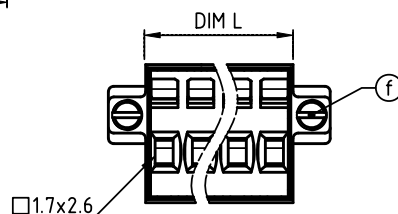
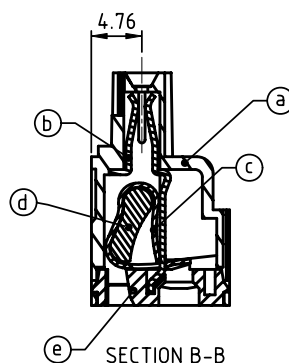
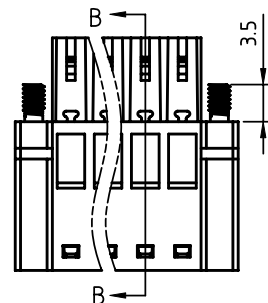
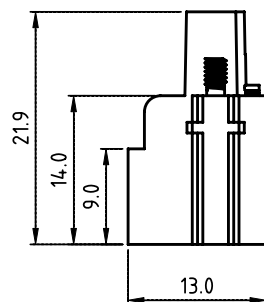


PRODUCT NUMBER	PITCH
HNxx10x200J0G	3.50 mm

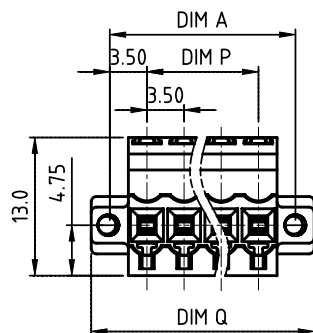

Material:

- Item a Terminal Body: Thermoplastic (UL94V-0)
- Item b Female contact: Phbz, Tin plated
- Item c Spring clamp: Stainless Steel
- Item d Insulating spacer: Thermoplastic (UL94V-0)
- Item e Terminal Cover: Thermoplastic (UL94V-0)
- Item f Flange screw: Zinc plating"-slot type,M2.0

Electrical cULus

- Voltage rating: 300V
- Current rating: 10A
- Wire range:
- Solid wire(AWG): 14-26
- Stranded wire(AWG): 14-26
- Wire strip length: 10-11mm
- Withstanding Voltage: 1.6KV
- Operating temperature: -40°C to +115°C
- Safety Approval: cULus

DIMENSION

DIM L	Nx3.5
DIM P	(N-1)x3.5
DIM Q	(N+2)x3.5
DIM A	(N-1)x3.5+7.0

N=Number of poles

Poles	DIM L	DIM P	DIM Q	DIM A
2p-6p	±0.15	±0.15	±0.20	±0.15
7p-12p	±0.20	±0.20	±0.25	±0.20
13p-18p	±0.25	±0.25	±0.30	±0.25
19p-24p	±0.30	±0.30	±0.40	±0.30

PART NO.: HN xx 1 0 x 2 00J0 G

		Color	RoHS compliant (lead<4%) In copper Alloy
solid block	0	Black (RAL9005)	
No. of poles	2	Red (RAL3001/D)	
02 2 poles	3	Orange(RAL2011/P)	
03 3 poles	4	Yellow(RAL1018/A)	
...	5	Green(RAL6018/T)	
24 24 poles	6	Blue (RAL5015/A)	
	8	Grey(RAL7035/D)	
	9	White(RAL1102)	
	C	Green(RAL6018/U)	

mat'l. code				surface ASME Y14.5		tolerance ASME Y14.5		projection		product family																			
ltr				ecn no		dr		date		tolerances unless otherwise specified										TERMINAL BLOCK									
										angles linear X.±0.5 X.X±0.3 X*±1° X.XX±0.1										title									
								TERMINAL BLOCK																					
								SPRING CLAMP,PLUGGABLE PLUG,WITH FLANGE																					
															dwg no					sheet 1 of 1					size				
															HNxx10x200J0G					A									
															type					CUSTOMER Drawing									
sheet index				revision sheet		A 1																							