




Catalog No. HS4-30L

Description: HVYWALL HTSHK 3:1 BLK 4-3/0 9IN

UPC No 786210872018

Home > Connectivity & Grounding > Shrink-Kon > Heat shrinkable tube

Heavy-Wall Heat-Shrinkable Tubing for Cable Range 1 - 3/0 AWG, Expanded Diameter 1.1 Inch, Length 9 Inch, 600 Volt, 90 Degrees Continuous Use, Cross-Linked Polyolefin with Thermoplastic Adhesive Liner, Black

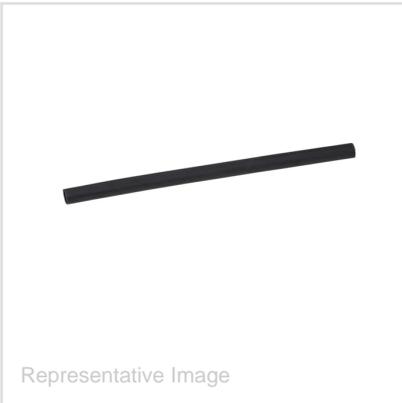

Representative Image

Descriptors

Category	Heat shrinkable tube
Special Features	Made of thermally stabilized cross-linked polyolefin, enabling a recovered wall thickness greater than that of the cable jacket replaced.

Specifications

Voltage Rating	600 V
Color	Black

Classifications

Brand Name	Shrink-Kon
------------	------------

Dimensions

Length	9 in , 228.6 mm
--------	-----------------

Compliance and Certifications

RoHS	RoHS3 Compliant
REACH	REACH 240 Compliant
TSCA	TSCA Section 6(h) Compliant
POPs	POPs 28 Compliant

ETIM	EC000217 Shrink tubing
Type	Heat-shrink
Model	Thick-walled
Shrink rate	3:1
Inner diameter before heat-shrink	27.94 mm
Inner diameter before heat-shrink	1.1 inch
Inner diameter after heat-shrink	8.89 mm



ETIM	EC000217 Shrink tubing
Inner diameter after heat-shrink	0.35 inch
Nominal diameter inch	Other
Wall thickness after shrinking	3.048 mm
Wall thickness after shrinking	0.12 inch
Length	0.2286 m
Length	0.75 ft
Operation temperature	-55-+110 °C
Operation temperature	-67-+230 °F
Colour	Black
Material	Polyolefin (PO-X)
Halogen free	N
With inner glue	N
Printable	N
UL approval	Y