

BPXX00060635101M00

Search by : [Part Number](#) [Characteristics](#) [Cross reference](#)




MP ?

Closed Magnetic Circuit Type

Series Pdf

Product detail	
L(mm) ±	6.0±0.2
W(mm) ±	6.0±0.2
T(mm) ±	3.5Max.
Inductance(uH)	100
Tolerance(±%)	20
Test Frequency	100kHz,0.1V
RDC(Ω)Max	0.375
Isat1(A)Typ	0.46
Isat2(A)Typ	0.52
Isat3(A)Typ	0.54
Irms(A)Typ	0.9
Operating Temperature	−40℃~125℃ (Including self - temperature rise)

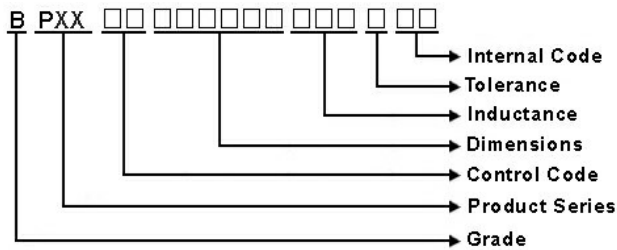

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

[Media Center](#)
[New Products](#)
[Events](#)
[Product Notices](#)

Contact Us

[Contact Info](#)
[Contact Form](#)
[Join Chilisín](#)

[Terms of Use](#)
[Privacy policy](#)
[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisín. All rights reserved.