

4802, Plug, solder terminal, screened, 3.5 mm, 2-pole, straight, UK-Connector



Description

- Solder terminal :
for cable mounting
- Data and Signal transfer
- Data and Signal Connectors 2-pole , shielded , straight

References

Alternative: Housing insulated [4802.1210](#)
Last order date: 30.06.2016


Technical Data

Diameter	3.5 mm
Number of Poles	2-pole
Ratings DC	1 A / 12 VDC
Ratings AC	1 A / 12 VAC
Dielectric Strength	500 VDC
Insulation Resistance	> 10000 MΩ @ 500 VDC

Allowable Operation Temperature	-20 °C to 70 °C
Terminal	solder terminal
Housings	screened
Style	straight
Lifetime	10000 Insertions

Detailed information on product approvals, code requirements, usage instructions and detailed test conditions can be looked up in [General Product Information](#)

Dimensions

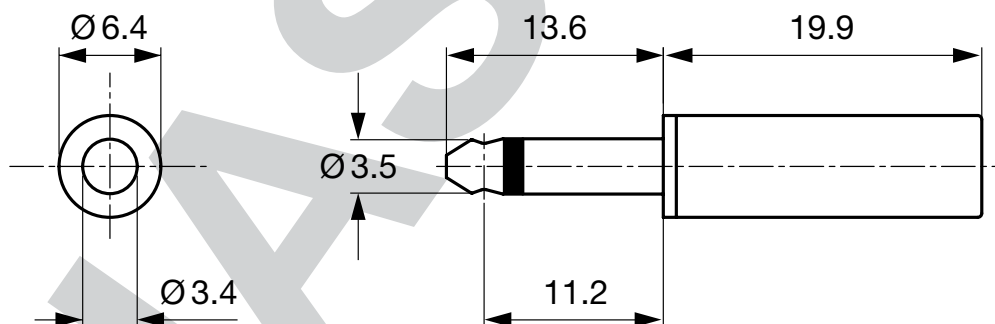

All Variants

Product group	Diameter [mm]	Number of Poles	Terminal	Order Number
Data and Signal Plug/ Sockets	3.5	2-pole	solder terminal	4802.1200

Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>

Packaging unit 100 Pcs