

APCA000606453R3T00

Search by :

Part Number

Characteristics

Cross reference



MP

Auto



SMD Shielded Type
Wire-winding Process & Ultra High Current

Series Pdf

Product detail	
L(mm) ±	6.0±0.2
W(mm) ±	6.3±0.2
T(mm) ±	4.5±0.3
Inductance(uH)	3.3
Tolerance(±%)	30
Test Frequency	100kHz,1V
RDC(Ω)Max	0.0247
Isat(A)Typ	3.5
Isat(A)Max	3.2
Irms(A)	3.7
Operating Temperature	−40℃~125℃(Including self - temperature rise)


Part Numbering

Dimensions

Packing

Recommended Pattern

Electrical Characteristics

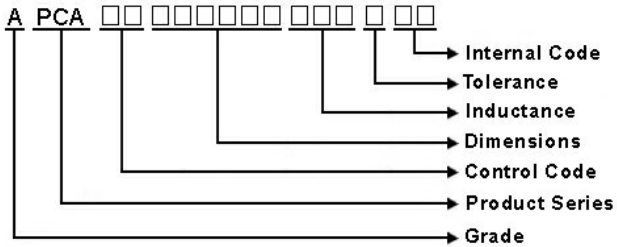

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisín](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisín. All rights reserved.