


Data Sheet | Item Number: 756-3106/040-003

Power cable; M12A socket; angled; M12A plug; angled; 4-pole; Length: 0.3 m


<https://www.wago.com/756-3106/040-003>

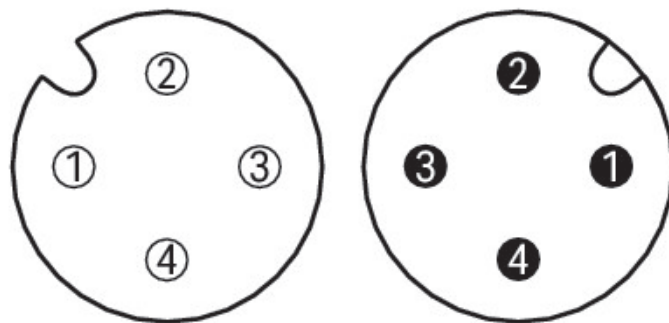

Pin 1 ... 4: 0.75 mm²

Diagram illustrating four horizontal lines, each labeled with a number (1 to 4) on both ends, representing different colors:

- 1 brown 1
- 2 white 2
- 3 blue 3
- 4 black 4

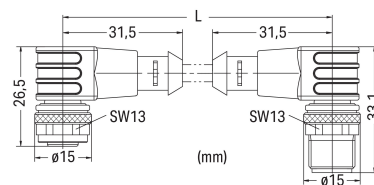

Dimensions in mm

Short description:

- PUR, halogen-free
- UL / CSA
- Suitable for drag chains
- Silicon- and CFC-free
- High resistance to microbes, hydrolysis, oil, chemicals and UV radiation
- High chemical resistance
- Cable used: UL listed

Technical data

Operating voltage	250 VAC/DC
Insulation resistance	$>10^9 \Omega$
Conductor resistance	$\leq 26 \Omega/\text{km}$

Mechanical data		
Weight		45 g

Commercial data		
PU (SPU)		1 pcs
Packaging type		Box
Country of origin		DE
GTIN		4045454127039
Customs tariff number		85444290900
End of Sale		2024-05-01
End of Production		2024-05-15
End of Delivery		2024-06-01
End of Service and Repair		2025-06-01

Product Classification		
UNSPSC		26121604
eCl@ss 10.0		27-06-18-01
eCl@ss 9.0		27-06-18-01
ETIM 9.0		EC001855
ECCN		NO US CLASSIFICATION

Approvals / Certificates

General approvals



Approval	Standard	Certificate Name
UL Underwriters Laboratories Inc.	UL 2238	E519602

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 756-3106/040-003	



Documentation

System Description		
I/O-SYSTEM – SPEED-WAY, General Product Information	pdf 1035.20 KB	

CAD/CAE-Data

CAE data		
WSCAD Universe 756-3106/040-003		

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com