




Part Number : [467083624](#)

Product Description : EXTreme Ten60Power Terminal Position Assurance (TPA) Retainer, for Assembly with 24 Signal / 6 Power Circuits

Series Number : 46708

Status : Active

Product Category : Connector Accessories

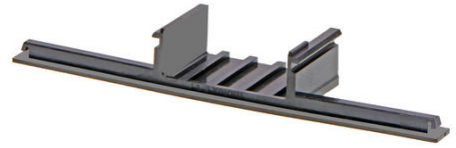

Documents and Resources

Drawings

[467083624 sd.pdf](#)


[PK-46708-0002-001.pdf](#)

Specifications

[PS-173693-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Connector Accessories
Series	46708
Description	EXTreme Ten60Power Terminal Position Assurance (TPA) Retainer, for Assembly with 24 Signal / 6 Power Circuits
Component Type	Terminal Position Assurance (TPA)
Keyword	Ten60
Product Name	EXTreme Ten60Power
UPC	889056279017

Physical

Circuits (Loaded)	30
Circuits (maximum)	30
Color - Resin	Black
Lock to Mating Part	Yes
Material - Resin	Polybutylene Terephthalate (PBT)
Net Weight	1.880/g
Packaging Type	Bag
Temperature Range - Operating	-40° to +105°C

Mates With / Use With

Use with Part(s)

Description	Part Number
EXTreme Ten60Power Wire-to-Board Receptacle Housings	<u>172510</u>
EXTreme Ten60Power Panel-to-Board Receptacle Housings	<u>172512</u>

This document was generated on May 13, 2026