

APSD00030321R82T00

Search by :

[Part Number](#)
[Characteristics](#)
[Cross reference](#)


[MP](#) [Auto](#) [?](#)

Unshielded Type

[Series Pdf](#)

[RoHSREACHCoC](#)

Product detail

L(mm) ±	3.3±0.3
W(mm) ±	3.0±0.3
T(mm) ±	2.1±0.3
Inductance(uH)	0.82
Tolerance(±%)	30
Test Frequency	7.96 MHz,1 V
RDC(Ω)Max	0.06
Isat(A)	2.2
Operating Temperature	-40°C~125°C(Including self - temperature rise)


Part Numbering

Dimensions

Packing

Recommended Pattern

Electrical Characteristics

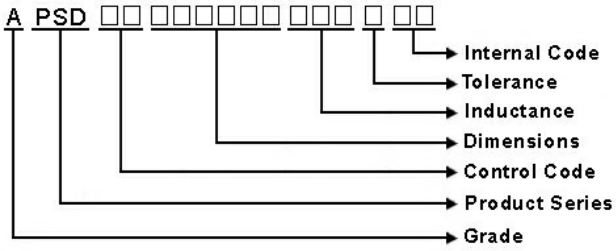

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

- [Media Center](#)
- [New Products](#)
- [Events](#)
- [Product Notices](#)

Contact Us

- [Contact Info](#)
- [Contact Form](#)
- [Join Chilisin](#)

- [Terms of Use](#)
- [Privacy policy](#)
- [Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.