



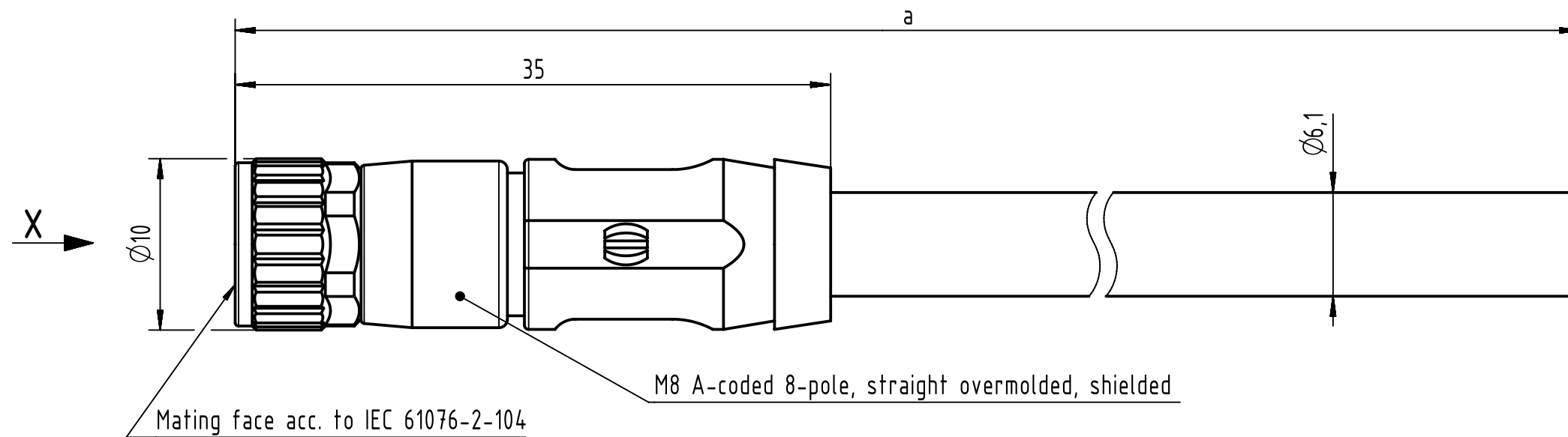

Shield

1	white
2	brown
3	green
4	yellow
5	grey
6	pink
7	blue
8	red

 
 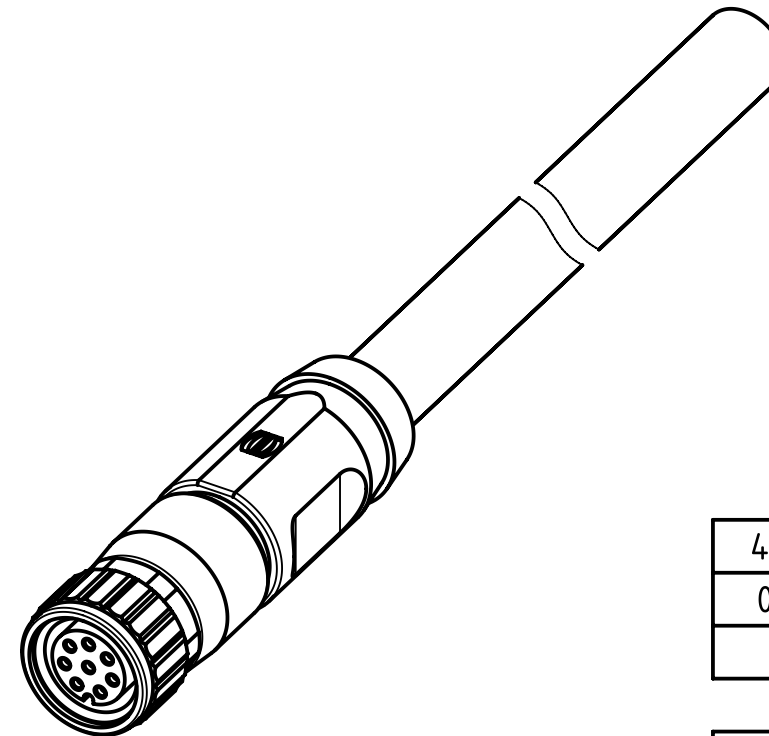


4.0 to 100	±1%
0.1 to 3.9	+0.04
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
0.1	XXX=001	
Step	a [m]	<u>XXX</u>

Part no.	2134B2008XXXXXX
Type of cable	XX
PVC grey, 8x0.14mm ²	XX=21
TPU black, 8x0.14mm ²	XX=22

- Protection level: IP67
- Temperature range: -30°C ... +80°C

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
		All rights reserved		Created by STOCHECIC		Inspected by COSTEA		Standardisation MUNTEANV	
Department HCS - RO				STOCECI		COSTEA		Date 2018-12-12	
				Title M8 Shielded Assy 8-poles st/- f/-				State Final Release	
HARTING Customised Solutions D-32339 Espelkamp								Doc-Key / ECM-Nr. 100686394/UGD/000/B 500000144261	
		Type TB		Number 2134B2008XXXXX				Rev. B	
								Page 1/1	