

# CES-SRC-BK - Cable sleeve



0801718  
<https://www.phoenixcontact.com/us/products/0801718>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable sleeve, small, no. of conductors: 1, type: Round cable, closed, external cable diameter: 1x 2 mm ... 11 mm, material: NBR, color: black, length: 29.5 mm, width: 19.5 mm, height: 17 mm

## Product description

Unslotted sleeves for accommodating cables and lines with a diameter of 2 ... 11 mm, can be used in CES sealing frames

## Commercial data

Item number	0801718
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF67
Product key	BF7CCX
Catalog page	Page 678 (C-2-2019)
GTIN	4046356675185
Weight per piece (including packing)	9.03 g
Weight per piece (excluding packing)	9.03 g
Customs tariff number	40169997
Country of origin	TW

# CES-SRC-BK - Cable sleeve




0801718  
<https://www.phoenixcontact.com/us/products/0801718>

## Technical data

### Product properties

Product type	Cable sleeve
No. of conductors	1

### Dimensions

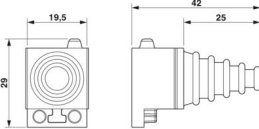Dimensional drawing	
Width	19.5 mm
Height	17 mm
Length	29.5 mm

### Material specifications

Material	NBR
----------	-----

### Cable/line

External cable diameter	1x 2 mm ... 11 mm
-------------------------	-------------------

### Characteristics

Seal size	small
Design, Format	Round cable
Design, Cable seal	closed

### Environmental and real-life conditions

Ambient conditions	
Degree of protection	IP54 IP65 (When using cable ties in combination with the installation direction to the side or downwards)
Ambient temperature (operation)	-40 °C ... 125 °C (static)

### Mounting

Assembly note	IP54: for vertical sealing frame mounting/for horizontal sealing frame mounting (downward cable outlet direction). IP65: vertical mounting/horizontal mounting (downward cable outlet direction) of the sealing frame directly on the housing panel and use of a 3.6 mm wide cable binder (e.g., item 3240744).
---------------	---

# CES-SRC-BK - Cable sleeve


0801718

<https://www.phoenixcontact.com/us/products/0801718>



## Drawings

Dimensional drawing

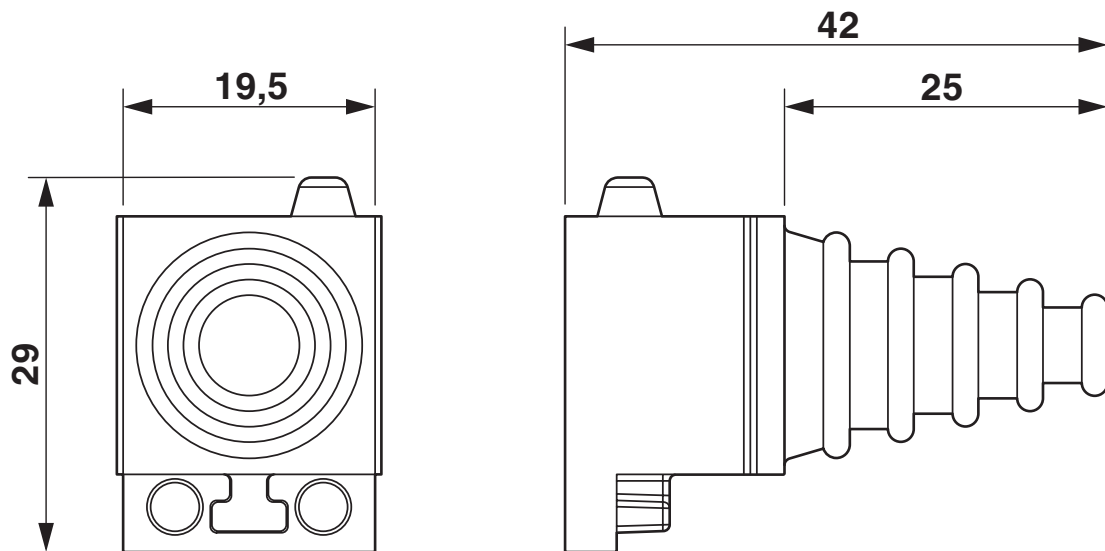

Dimensional drawing

# CES-SRC-BK - Cable sleeve



0801718

<https://www.phoenixcontact.com/us/products/0801718>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/0801718>

### DNV

Approval ID: TAE00003VJ

# CES-SRC-BK - Cable sleeve



0801718

<https://www.phoenixcontact.com/us/products/0801718>

## Classifications

### ECLASS

ECLASS-11.0	27144425
ECLASS-12.0	27144425
ECLASS-13.0	27144425

### ETIM

ETIM 9.0	EC000451
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# CES-SRC-BK - Cable sleeve



0801718

<https://www.phoenixcontact.com/us/products/0801718>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

# CES-SRC-BK - Cable sleeve

0801718

<https://www.phoenixcontact.com/us/products/0801718>



## Accessories

### WT-HF 2,5X98 BK - Cable tie

3240733

<https://www.phoenixcontact.com/us/products/3240733>



Cable binders for quick and secure bundling, standard version

---

### CES-B10-HFFS-PLBK - Sealing frame

0801663

<https://www.phoenixcontact.com/us/products/0801663>



Sealing frame, With locking latch, design: B10, Number of cable seals (small): 6, material: PA (halogen-free), color: black, length: 99.2 mm, width: 58 mm, height: 20 mm

## CES-SRC-BK - Cable sleeve

0801718

<https://www.phoenixcontact.com/us/products/0801718>



## CES-B16-HFFS-PLBK - Sealing frame

0801662

<https://www.phoenixcontact.com/us/products/0801662>



Sealing frame, With locking latch, design: B16, Number of cable seals (small): 8, material: PA (halogen-free), color: black, length: 120 mm, width: 58 mm, height: 20 mm

---

## CES-B24-HFFS-PLBK - Sealing frame

0801661

<https://www.phoenixcontact.com/us/products/0801661>



Sealing frame, With locking latch, design: B24, Number of cable seals (small): 10, material: PA (halogen-free), color: black, length: 147 mm, width: 58 mm, height: 20 mm



## CES-SRC-BK - Cable sleeve

0801718

<https://www.phoenixcontact.com/us/products/0801718>



## CES-B10-SFFS-PLBK - Sealing frame

0801660

<https://www.phoenixcontact.com/us/products/0801660>



Sealing frame, with screw locking, design: B10, Number of cable seals (small): 6, material: PA (halogen-free), color: black, length: 99.2 mm, width: 58 mm, height: 20 mm

---

## CES-B16-SFFS-PLBK - Sealing frame

0801659

<https://www.phoenixcontact.com/us/products/0801659>



Sealing frame, with screw locking, design: B16, Number of cable seals (small): 8, material: PA (halogen-free), color: black, length: 120 mm, width: 58 mm, height: 20 mm

# CES-SRC-BK - Cable sleeve

0801718

<https://www.phoenixcontact.com/us/products/0801718>



## CES-B24-SFFS-PLBK - Sealing frame

0801658

<https://www.phoenixcontact.com/us/products/0801658>



Sealing frame, with screw locking, design: B24, Number of cable seals (small): 10, material: PA (halogen-free), color: black, length: 147 mm, width: 58 mm, height: 20 mm

---

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)