


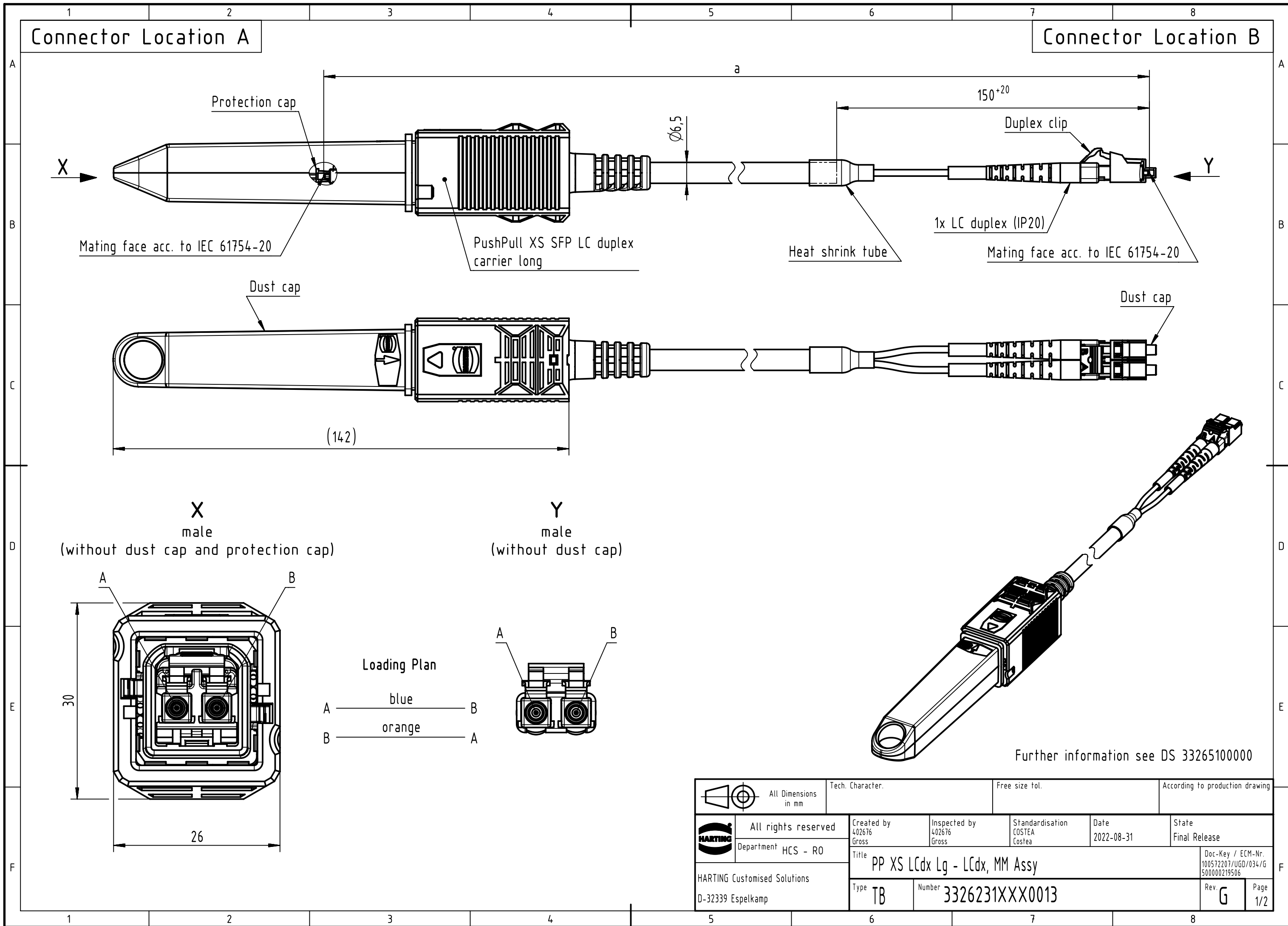

	1	2	3	4	5	6	7	8
A								
B								
C	28	33262311250013	FO Breakout Cable, MM, 50/125µm, PUR, black, bend tolerant OM3	125	±1%			
	27	33262311000013		100				
	26	33262310900013		90				
	25	33262310800013		80				
	24	33262310700013		70				
	23	33262310600013		60				
	22	33262310500013		50				
	21	33262310450013		45				
	20	33262310400013		40				
	19	33262310350013		35				
D	18	33262310300013		30				
	17	33262310250013		25				
	16	33262310200013		20				
	15	33262310150013		15				
	14	33262310140013		14				
	13	33262310130013		13				
	12	33262310120013		12				
E	11	33262310110013		11	±0.03			
	10	33262310100013		10				
	9	33262310090013		9				
	8	33262310080013		8				
	7	33262310070013		7				
	6	33262310060013		6				
	5	33262310050013		5				
F	4	33262310040013		4				
	3	33262310030013		3				
	2	33262310020013		2				
	1	33262310010013		1				
	Cont. no.	Part no.	Type of cable	Dim. a[m]				



HARTING Customised Solutions
D-32339 Espelkamp

All rights reserved

Department HCS - RO

Created by
402676
Gross

Inspected by
402676
Gross

Title
PP XS LCdx Lg - LCdx, MM Assy

Type
TB

Standardisation
COSTEA
Costea

Date
2022-08-31

Number
3326231XXX0013

Doc-Key / ECM-Nr.
100572207/UGD/034/G
500000219506

Rev.
G

Page
2/2

Tech. Character.

Free size tol.

According to production drawing