


Part Number : [640057400](#)

Product Description : Power Crimp Tool Head for
Terminals 22-10 AWG Wire

Series Number : 207129

Status : Active

Product Category : Crimp Presses and Crimp Hand
Tools

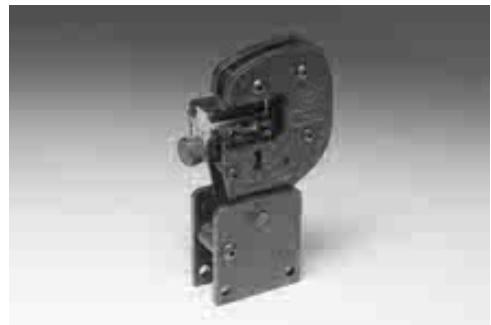

Documents & Resources

Tooling Specifications

[ATS-640057400-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Not Relevant
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of ComplianceAdditional Product Compliance Information**Part Details****General**

Status	Active
Category	Crimp Presses and Crimp Hand Tools
Series	207129
Description	Power Crimp Tool Head for Terminals 22-10 AWG Wire
Comments	See Tooling Specification (PDF) Above; Type: AT
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic
More Detailed Tech Information	toolingsupport@molex.com
Product Name	N/A
Tool Type	Battery Powered Hand Tool
UPC	883906134501
Warranty Disclaimer	<p>CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer.</p> <p>Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.</p>

Physical

Net Weight	0.001/kg
------------	----------

Mates With / Use With

Use with Part(s)

Description	Part Number
Battery Powered Crimping Tool, 110V	<u>638160270</u>
Battery Powered Crimping Tool, 220V	<u>638160280</u>
Electric Crimping Machine CS 300	<u>638161500</u>

Applicable Parts

Description	Part Number
Perma-Seal Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 10 (M5), Carton	<u>191640003</u>
Perma-Seal Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 1/4" (M6), Carton	<u>191640004</u>
Perma-Seal Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 3/8" (M9), Carton	<u>191640005</u>
Perma-Seal Spade Tongue Terminal for 22-18 AWG Wire, Stud Size 6 (M3.5), Carton	<u>191640006</u>
Perma-Seal Spade Tongue Terminal for 22-18 AWG Wire, Stud Size 8 (M4), Carton	<u>191640007</u>
Perma-Seal Spade Tongue Terminal for 22-18 AWG Wire, Stud Size 10 (M5), Carton	<u>191640008</u>
Perma-Seal 3-Way Connector Assembly for 22-18 AWG Wire, Carton	<u>191640011</u>
Perma-Seal Butt Splice for 22-18 AWG Wire, Carton	<u>191640013</u>

Perma-Seal Butt Splice for 22-18 AWG Wire, Mylar Tape Carrier	<u>191640014</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 3/8" (M9), Carton	<u>191640020</u>
Perma-Seal Hook Tongue Terminal for 16-14 AWG Wire, Stud Size 10 (M5), Carton	<u>191640021</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 1/4" (M6), Carton	<u>191640026</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 5/16" (M8), Carton	<u>191640027</u>
Perma-Seal Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Carton	<u>191640028</u>
Perma-Seal Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 8 (M4), Carton	<u>191640029</u>
Perma-Seal Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 10 (M5), Carton	<u>191640030</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Carton	<u>191640032</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 8 (M4), Carton	<u>191640033</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 10 (M5), Carton	<u>191640034</u>
Perma-Seal 3-Way Connector Assembly for 16-14 AWG Wire, Carton	<u>191640042</u>
Perma-Seal Step Down Butt Splice from 16/14 to 22/18 AWG Wire, Carton	<u>191640043</u>
Perma-Seal Butt Splice for 16-14 AWG Wire, Carton	<u>191640044</u>
Perma-Seal Butt Splice for 16-14	<u>191640045</u>

AWG Wire, Mylar Tape Carrier	
Perma-Seal Butt Splice for 12-10 AWG Wire, Carton	<u>191640056</u>
Perma-Seal Butt Splice for 12-10 AWG Wire, Mylar Tape Carrier	<u>191640057</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/2" (M12), Carton	<u>191640058</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 6 (M3.5), Carton	<u>191640061</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Carton	<u>191640062</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Carton	<u>191640065</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/4" (M6), Carton	<u>191640066</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 5/16" (M8), Carton	<u>191640067</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 3/8" (M9), Carton	<u>191640068</u>
Perma-Seal Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 6 (M3.5), Carton	<u>191640069</u>
Perma-Seal Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Carton	<u>191640070</u>
Perma-Seal 3-Way Connector Assembly for 12-10 AWG Wire, Carton	<u>191640074</u>
Perma-Seal Step Down Butt Splice from 12/10 to 16/14 AWG Wire, Carton	<u>191640077</u>
Perma-Seal Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 6 (M3.5), Carton	<u>191640085</u>

Perma-Seal Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 8 (M4), Carton	<u>191640086</u>
Perma-Seal Hook Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Carton	<u>191640141</u>
Perma-Seal Hook Tongue Terminal for 16-14 AWG Wire, Stud Size 8 (M4), Carton	<u>191640142</u>
Perma-Seal Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191640306</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 3/8" (M9), Mylar Tape Carrier	<u>191640307</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 1/4" (M6), Mylar Tape Carrier	<u>191640308</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 5/16" (M8), Mylar Tape Carrier	<u>191640309</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier	<u>191640310</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191640311</u>
Perma-Seal Ring Tongue Terminal for 16-14 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191640312</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191640316</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 1/4" (M6), Mylar Tape Carrier	<u>191640317</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 5/16" (M8), Mylar Tape Carrier	<u>191640318</u>
Perma-Seal Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191640419</u>

Perma-Seal Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 5/16" (M8), Carton	<u>191640435</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 3/8" (M9), Mylar Tape Carrier	<u>191640857</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191640938</u>
Perma-Seal Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191640939</u>
Perma-Seal Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier	<u>191640948</u>

This document was generated on Sep 16, 2025