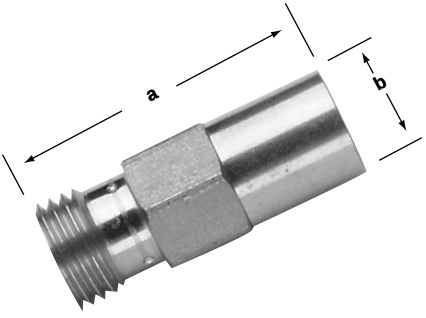
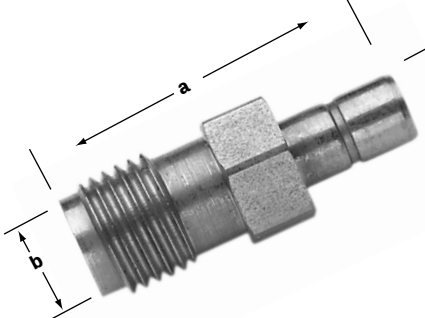
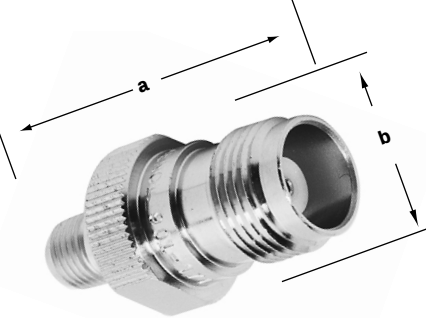
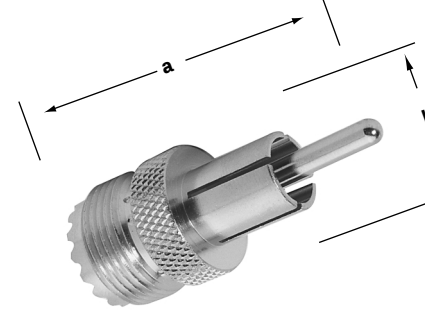


Adapters, Between Series Straight, Jack to Plug or Jack to Jack

Amphenol®

Fig. 1  SMA Jack to SMB Plug (female contact) 901-9034 VSWR: 1.08 max. DC-4 GHz	Fig. 2  SMA Jack to SMB Jack (male contact) 901-9033 VSWR: 1.08 max. DC-4 GHz
Fig. 3  SMA Jack to TNC Jack 901-171 VSWR: 1.3 max. DC-12.4 GHz	Fig. 4  UHF Jack to RCA Plug 83-10

STRAIGHT ADAPTERS - JACK TO PLUG OR JACK TO JACK

Adapter Ends		Dimension, inch (millimeters)		Notes		Military Number	Amphenol Number	Fig.
		a	b	Plt.	Ins.			
SMA Jack	SMB Plug	.750 (19.1)	.250 (6.4) hex.	P1	D1	-	901-9034	1
SMA Jack	SMB Jack	.705 (17.9)	.250 (6.4) hex.	P12	D1	-	901-9033	2
SMA Jack	TNC Jack	1.12 (28.6)	.562 (14.3) dia.	P51	D1	-	901-171	3
UHF Jack	RCA Plug	1.64 (41.7)	.650 (16.5) dia.	P2	D33	-	83-10	4