


PART NAME	SNB-SERIES NEMA SHEET METAL BOXES	PART No.	SNB-3730 THRU SNB-3736 & SNB-3738 THRU SNB-3741	REV. DATE	2-7-11
-----------	-----------------------------------	----------	---	-----------	--------

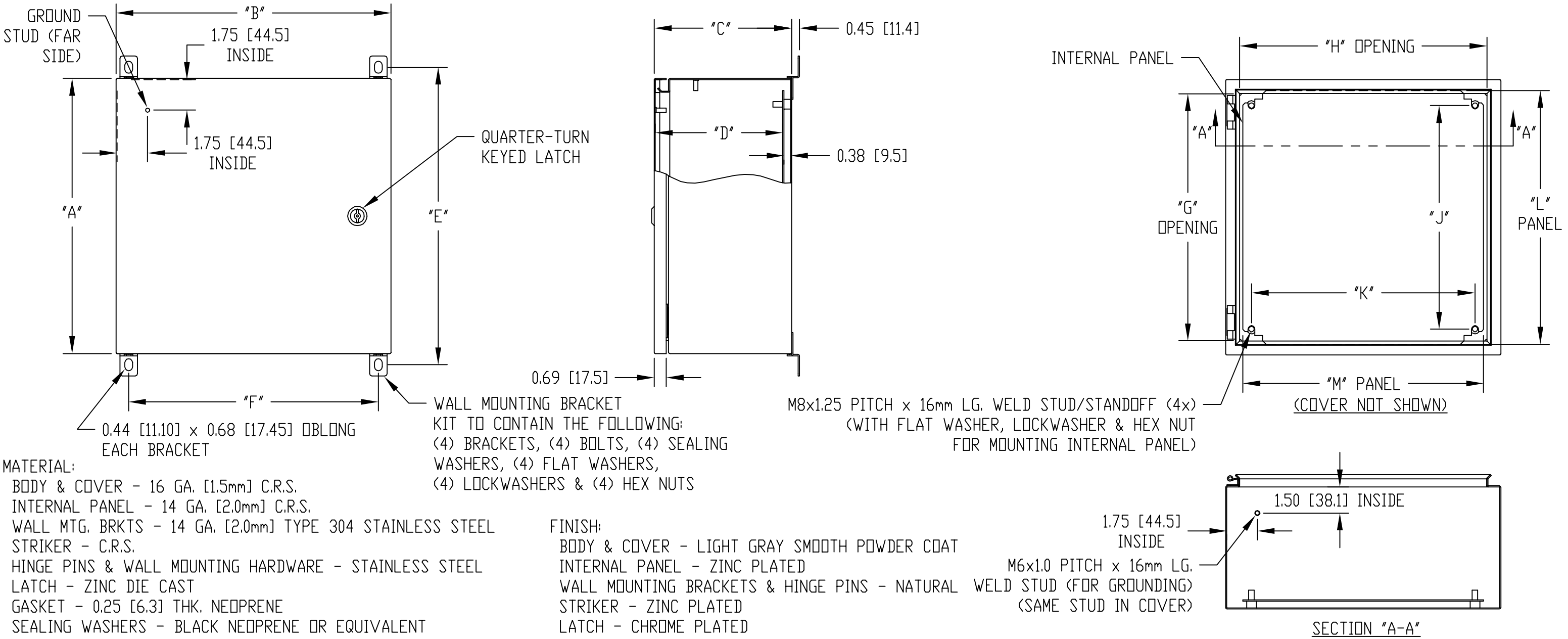

PART NO.	"A"	"B"	"C"	"D"	"E"	"F"	"G"	"H"	"J"	"K"	"L"	"M"
SNB-3730	9.84 [250]	7.87 [200]	5.91 [150]	5.33 [135.3]	11.12 [282.3]	6.42 [163]	8.25 [209.5]	6.28 [159.5]	6.89 [175]	4.92 [125]	8.46 [215]	5.91 [150]
SNB-3731	11.81 [300]	9.84 [250]	5.91 [150]	5.33 [135.3]	13.08 [332.3]	8.39 [213]	10.22 [259.5]	8.25 [209.5]	8.86 [225]	6.89 [175]	10.43 [265]	7.87 [200]
SNB-3732	11.81 [300]	9.84 [250]	7.87 [200]	7.29 [185.1]	13.08 [332.3]	8.39 [213]	10.22 [259.5]	8.25 [209.5]	8.86 [225]	6.89 [175]	10.43 [265]	7.87 [200]
SNB-3733	11.81 [300]	11.81 [300]	5.91 [150]	5.33 [135.3]	13.08 [332.3]	10.35 [263]	10.22 [259.5]	10.22 [259.5]	8.86 [225]	8.86 [225]	10.43 [265]	9.84 [250]
SNB-3734	11.81 [300]	11.81 [300]	7.87 [200]	7.29 [185.1]	13.08 [332.3]	10.35 [263]	10.22 [259.5]	10.22 [259.5]	8.86 [225]	8.86 [225]	10.43 [265]	9.84 [250]
SNB-3735	15.75 [400]	11.81 [300]	5.91 [150]	5.33 [135.3]	17.02 [432.3]	10.35 [263]	14.16 [359.5]	10.22 [259.5]	12.80 [325]	8.86 [225]	14.37 [365]	9.84 [250]
SNB-3736	15.75 [400]	11.81 [300]	7.87 [200]	7.29 [185.1]	17.02 [432.3]	10.35 [263]	14.16 [359.5]	10.22 [259.5]	12.80 [325]	8.86 [225]	14.37 [365]	9.84 [250]
SNB-3738	7.87 [200]	5.91 [150]	5.91 [150]	5.33 [135.3]	9.15 [232.3]	4.45 [113]	6.28 [159.5]	4.31 [109.5]	4.92 [125]	2.96 [75]	6.50 [165]	3.94 [100]
SNB-3739	7.87 [200]	7.87 [200]	3.98 [101]	3.40 [86.4]	9.15 [232.3]	6.42 [163]	6.28 [159.5]	6.28 [159.5]	4.92 [125]	4.92 [125]	6.50 [165]	5.91 [150]
SNB-3740	9.84 [250]	9.84 [250]	5.91 [150]	5.33 [135.3]	11.12 [282.3]	8.39 [213]	8.25 [209.5]	8.25 [209.5]	6.89 [175]	6.89 [175]	8.46 [215]	7.87 [200]
SNB-3741	9.84 [250]	7.87 [200]	3.98 [101]	3.40 [86.4]	11.12 [282.3]	6.42 [163]	8.25 [209.5]	6.28 [159.5]	6.89 [175]	4.92 [125]	8.46 [215]	5.91 [150]