

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200710043

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single Keyway with PG9 Cable Fitting, Straight Female, 5 Poles, Cable Diameter 4.10-8.10mm

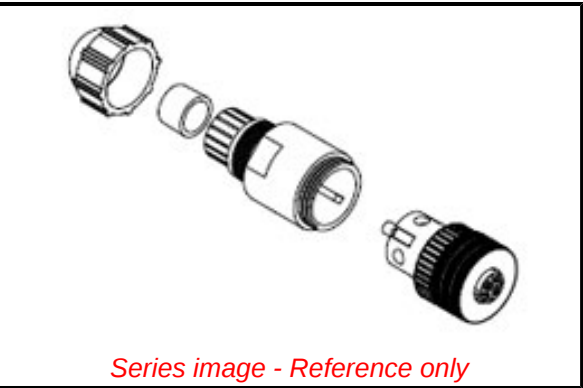

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	120071
Approvals	cCSAus certified
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Type	Field Attachable Connector
UPC	78172553111
Physical	
Cable Diameter	4.10 - 8.10mm (.161-.319")
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	Single
Material - Connector Body	PA
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Silver
Net Weight	36.730/g
Orientation	Straight
Poles	5
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	18
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	30V AC / 36V DC
Material Info	
Engineering Number	8A5000-32
Reference - Drawing Numbers	
Sales Drawing	SD-120071-006

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

120071 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION