


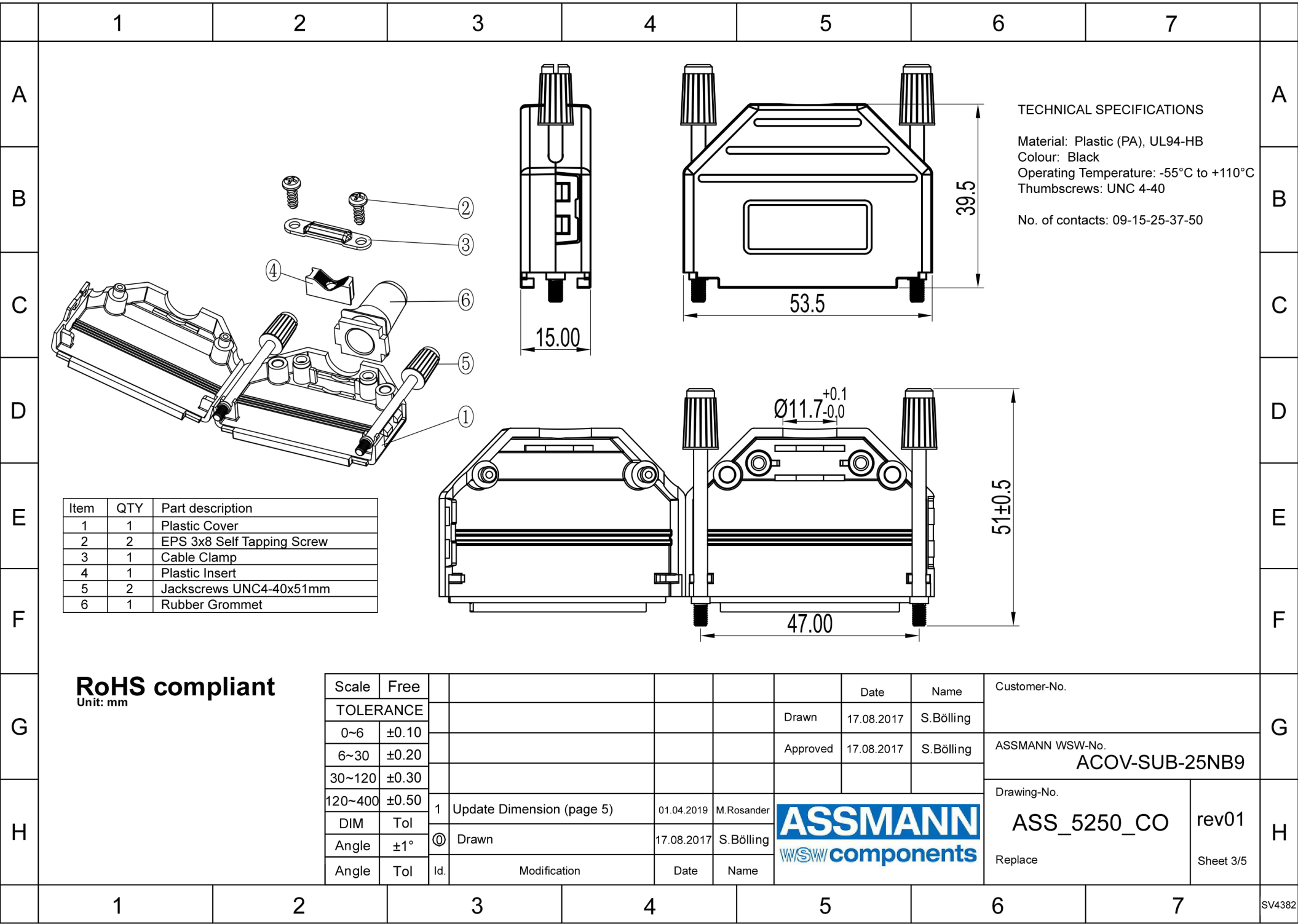

TECHNICAL SPECIFICATIONS

Material: Plastic (PA), UL94-HB
Colour: Black
Operating Temperature: -55°C to +110°C
Thumbscrews: UNC 4-40
No. of contacts: 09-15-25-37-50

Item	QTY	Part description
1	1	Plastic Cover
2	2	EPS 3x8 Self Tapping Screw
3	1	Cable Clamp
4	1	Plastic Insert
5	2	Jackscrews UNC4-40x51mm
6	1	Rubber Grommet

RoHS compliant
Unit: mm

Scale	Free					Date	Name	Customer-No.
TOLERANCE						Drawn	17.08.2017	S.Bölling
0~6	±0.10					Approved	17.08.2017	S.Bölling
6~30	±0.20							
30~120	±0.30							
120~400	±0.50	1	Update Dimension (page 5)	01.04.2019	M.Rosander	ASSMANN WSW components		
DIM	Tol	Ⓢ	Drawn	17.08.2017	S.Bölling			
Angle	±1°	Ⓢ						
Angle	Tol	Id.	Modification	Date	Name			

ASSMANN WSW-No. ACOV-SUB-25NB9	
Drawing-No. ASS_5250_CO	rev01
Replace	Sheet 3/5

