



Search



narrow your search

Products

- ? Controls Monitoring and Lighting (353)
- ? Machine Safety (1726)
- ? Sensors (7015)
- ? Switches (9585)

Technology

- ? Control and Instrumentation(1051)
- ? Electromechanical (9146)
- ? Magnetic (505)
- ? Microstructure (2298)
- ? Thick Film(1764)
- ? More...


Need Help?

Click here to contact us



343P1K Trimmers

(Home: Products)

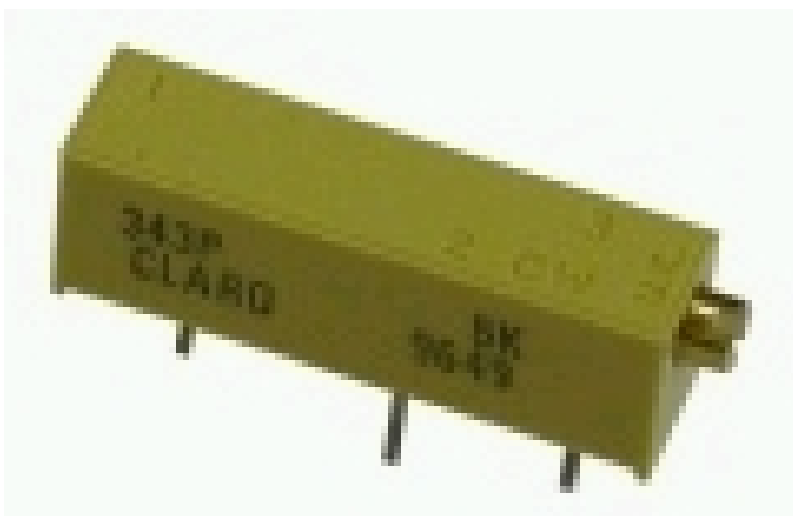

Actual product appearance may vary.

343 Series Trimmer, 1 kOhm, 0.75 W, 20 Turns, Rectangular Body, Horizontal Shaft

Sales & Service



Distributor Inventory



Overview

Specs

Documentation

Application Notes

Description

The 343 Series is a low profile, 19.05 mm (3/4 in.) rectangular, multturn trimmer. Made in accordance to MIL-R-22097 standards, the 343 is sealed for cleaning in common solvents.

Features

Features

- ? 20-turns
- ? 0.75 Watt
- ? Cermet element
- ? Low cost
- ? Low profile - only 6.35 mm (1/4 in) high brush contact and unique "T" slider block design assure CRV of 3 % or 3 Ohms contact idles at stops

Potential Applications

Potential Applications

- ? Voltage divider circuits
- ? Telecommunications