


Product Line

- Single Pair Ethernet >
- ZConnect >
- Ceres >
- Accessory
- Large Size
- Macro Size
- Middle Size
- Mini Size
- Others (GBD)
- Others (MAB)
- Others (PLD)
- Standard Size
- X-Lok >
- M Series >
- FLOS & FLOS+ >
- Power >
- RBL >
- HS-Lok >
- MM5A-2000

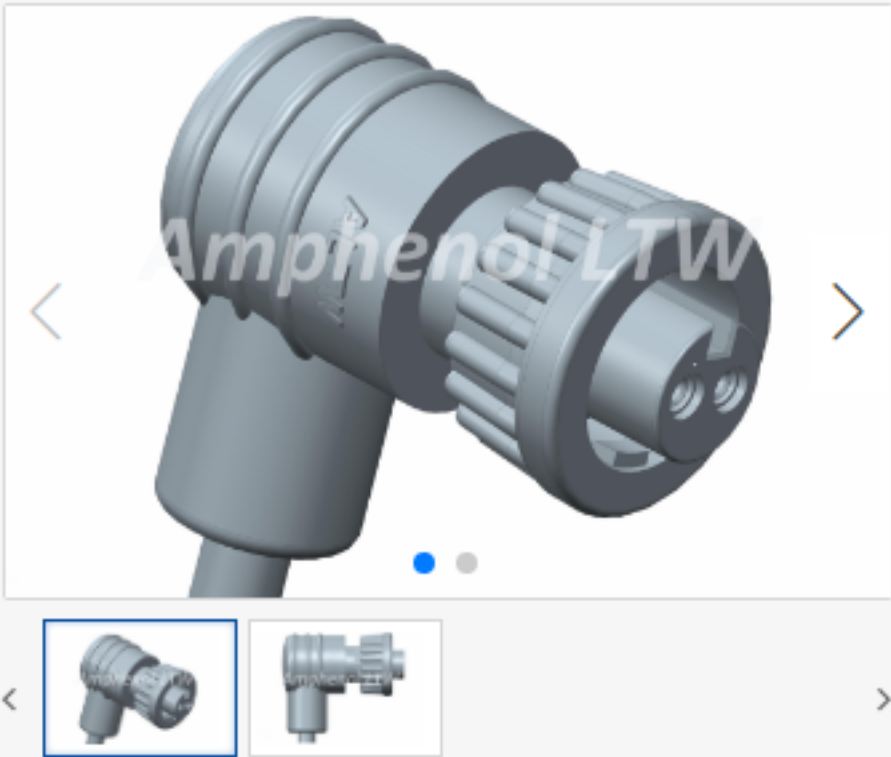

AU-06BFFM-LR6A01

- Operating Temperature: -20°C ~ +80°C
- Transmission Speed: N/A
- Shielded: Plastic, Non-shielded
- Jacket Material: PVC
- Certificate: N/A

You must login first for view the price

Quantity

-1+

Check Stock

Add to Cart

Inquiry



Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type

Search

-0+

-0+

-0+

-0+

Add to Cart

Inquiry

ABOUT AMPHENOL LTW

SUPPORT

PARTNERS

DOWNLOAD CENTER

FEEDBACK

- Heavy Duty Shielded >
- RJ >
- USB >
- SSL >
- HDMI >
- DVI >
- Fiber Optic >
- RF >
- Cable Joiner >
- Cable Gland >
- Pressure Relief Vent >
- LED Light Guide >
- D-Sub >

Specifications

Download / CAD

Nominal Current

2A

Connector Type

Overmolded

Shielded

Plastic, Non-shielded

No. of Contacts

06

Connector Gender

Female

Backshell

Right Angle

Mating Style

2 Points Lock

IP Rating

IPX6

Assembly Style

N/A

More Options

People Also Bought

