

The Maxclip System
Find a Clip

Check Distributor Stock

Enter a part number for
pricing and availability.

go!

Application Info

[Installation Demo Video](#)

[Thermal Performance](#)

[Tabless Packages](#)

[Tin Plated Pins](#)

[Shock and Vibration Testing](#)

[Choosing a Clip](#)

[Interface material selection](#)

Clip Over Edge Clips

Part Number: CLP212G

Clip over edge

RoHS  Compliant

Product
Change
Notice 

Force: 21 N [4.7 lbs]

Width: 10 mm [0.39 in]

Thickness: 0.5 mm [0.02 in]

Part Number: CLP212MG

Clip over edge

RoHS  Compliant

Force: 36 N [8.1 lbs]

Width: 13.3 mm [0.519 in]

Thickness: 0.6 mm [0.02 in]

Part Number: CLP212PG

Clip over edge

RoHS  Compliant

Force: 21 N [4.7 lbs]

Width: 10 mm [0.39 in]

Thickness: 0.5 mm [0.02 in]

Part Number: CLP212SG

Clip over edge

RoHS  Compliant

Force: 20 N [4.5 lbs]

Width: 7 mm [0.28 in]

Thickness: 0.5 mm [0.02 in]

Part Number: CLP212TG






Clip over edge

RoHS  Compliant

Force: 34 N [7.6 lbs]

Width: 10 mm [0.39 in]

Thickness: 0.6 mm [0.02 in]

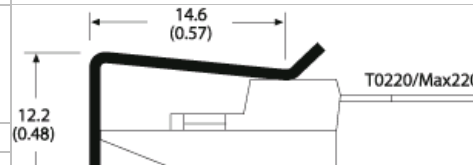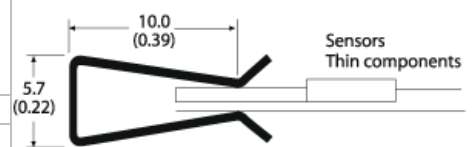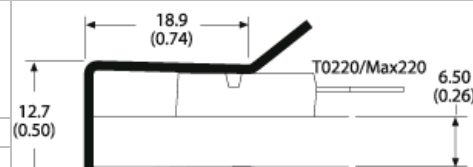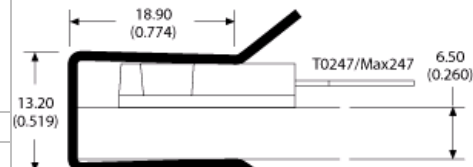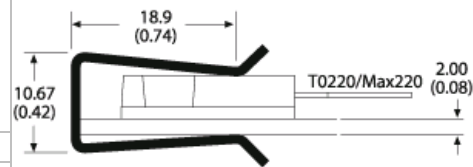

Customer Assistance

- Contact Us
- Get Design Assistance
- Find a Distributor
- Find a Sales Rep
- Request a Quote
- Placing an Order
- Terms and Conditions
- Returns

Popular Products

- Fans
- Extrusions
- Board Level
- Liquid Cooling
- Heat Pipe Technology
- Heat Sink Accessories
- Interface Materials

Our Company

- News and Events
- Management Team
- Worldwide Locations
- Disclaimer
- Customer Survey
- Privacy Policy
- Careers

Connect with Aavid

Like / Follow / Connect



© Copyright 2016 Aavid Thermalloy, LLC.

USA: 1.855.32.AAVID Europe: 39.051.764002 Asia: 86.21.6115.2000 x 8122