


Current refinements (click  to remove)

Search Tips

Region **USA**  Product Family **Military Standard Nylon Grommet Edging**  Text Search: 'GE192-L69'

Your search criteria matched only one product, shown below.

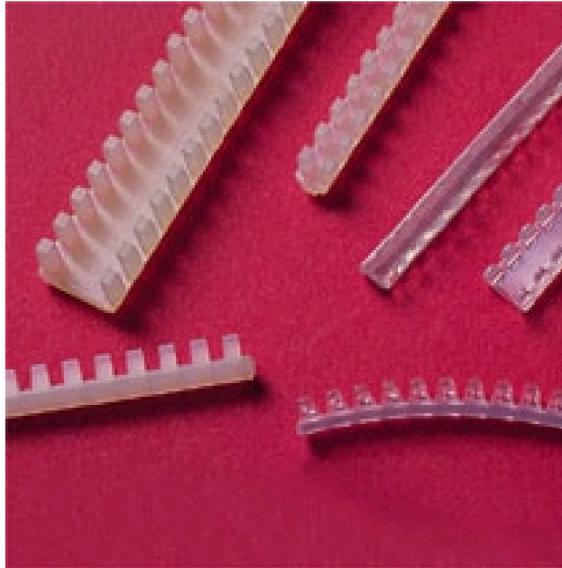

Part Number:	GE192-L69
RoHS Compliancy Status:	Compliant
Part Description:	Military Specification Nylon Grommet Edging in 12.75" strips.
Material:	Flame Retardant Nylon 6.6
Color:	Natural
Height (In.):	.23
Height (mm):	5.8
Length (In.):	12.75
Length (mm):	323.9
Width (In.):	.33
Width (mm):	8.3
Flammability Rating:	UL94 V-0
Outside Depth (In.):	.230
Outside Depth (mm):	5.8
Outside Width (In.):	.325
Outside Width (mm):	8.3
Panel Thickness Range (In.):	.128 – .192
Panel Thickness Range (mm)	3.3 – 4.9
Temperature Range:	-40°F to 149°F (-40°C to 65°C)
Min. Order UOM:	PC
Min. Order Qty.:	50
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to My Catalog	<input type="button" value="€"/>

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'My Catalog' features.