

Part Number : [1300060436](#)


Product Description : Mini-Change A-Size Single-Ended Cordset, 3 Poles, Female (90°) to Pigtail, 16 AWG, Yellow PVC Cable, 6.10m (20.0') Length

Series Number : 130006

Status : Active

Product Category : Circular Industrial Cordsets

Engineering Part Number : 103001A01F200

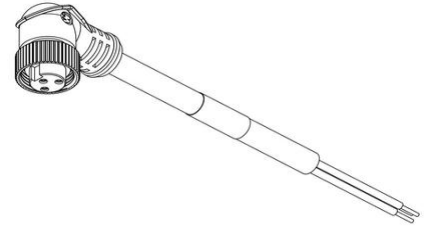


Documents and Resources

Drawings

[1300060436 sd.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|---|
| GADSL/IMDS | Not Relevant |
| China RoHS |  per SJ/T 11365-2006 |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Contains Lead per D(2025)7771-DC (04 Feb 2026) |
| EU RoHS | Compliant with Exemption 6(c) per EU 2015/863 |

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

UKCA - Declaration of Conformity

CE - Declaration of Conformity

Part Details

General

| | |
|--------------|---|
| Status | Active |
| Category | Circular Industrial Cordsets |
| Series | 130006 |
| Description | Mini-Change A-Size Single-Ended Cordset, 3 Poles, Female (90°) to Pigtail, 16 AWG, Yellow PVC Cable, 6.10m (20.0') Length |
| IP Rating | IP67 |
| Product Name | Mini-Change |
| Type | Single Ended |
| UPC | 78678843052 |

Agency

| | |
|-----|---------|
| CSA | LR6837 |
| UL | E152210 |

Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 13.0A |
| Voltage - Maximum | 600V |

Physical

| | |
|----------------------|-----------------|
| Cable Diameter | 10.41mm (.410") |
| Cable Length | 6.10m (20.0') |
| Color - Cable Jacket | Yellow |
| Connector End A | Mini-Change |
| Connector End B | Pigtail |

| | |
|-------------------------------|-------------------------|
| Coupling Style | Threaded |
| Gender | Female-Pigtail |
| Keyway | Single |
| LED Indicator | None |
| Material - Cable Jacket | PVC |
| Material - Connector Body | TPE |
| Material - Contact | Copper Alloy |
| Material - Coupling Nut | Black Epoxy Coated Zinc |
| Material - Plating Mating | Gold |
| Net Weight | 471.000/g |
| Orientation | 90° to Pigtail |
| Poles | 3 |
| Temperature Range - Operating | -20° to +105°C |
| Wire/Cable Type | STOOW |
| Wire Size (AWG) | 16 |

This document was generated on Apr 23, 2026