

## SKINTOP® CLICK

SKINTOP® CLICK, plastic cable gland with time-saving CLICK system, simple, free assembly and vibration protection, no thread required

### Info

The most innovative cable insertion system in the market for a fast and highly flexible assembly. Simply click in - turn to the left - turn to the right - finished. The result: fixed, centred, strain-relieved fitting and maximum protection class in a few seconds. In practical box available in the web catalogue



-  Good chemical resistance
-  Wide clamping range
-  Assembly time
-  Temperature-resistant
-  UV-resistant
-  Variety of approval certifications

### Benefits

Fewer parts, counter nut no longer needed  
 Save up to 70% of the time with the innovative CLICK system  
 Simple, free assembly in any position  
 Vibration protection  
 No thread required

Last Update (06.06.2023)

©2023 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## SKINTOP® CLICK

### Application range

Automation technology  
Solar applications  
Control cabinet manufacturing  
Measurement, control and electrical applications  
Air-conditioning technology

### Norm references / Approvals

UL File Nr. E79903

### Included

Included: disassembly tool

### Technical Data

|                        |                                                                                   |
|------------------------|-----------------------------------------------------------------------------------|
| Classification ETIM 5: | ETIM 5.0 Class-ID: EC000441<br>ETIM 5.0 Class-Description: Cable screw gland      |
| Classification ETIM 6: | ETIM 6.0 Class-ID: EC000441<br>ETIM 6.0 Class-Description: Cable screw gland      |
| Colour delivered:      | Silver grey (RAL 7001)<br>Light grey (RAL 7035)<br>Black (RAL 9005), UV-resistant |
| Material:              | Body: special polyamide<br>Seal: special elastomer                                |
| Protection rating:     | IP 68 - 4 bar (M12)<br>IP 68 - 5 bar (M16 - M25)<br>IP 68 - 1 bar (M32)           |
| Temperature range:     | Dynamic: -20 °C to +100 °C<br>Fixed: -40 °C to +100 °C                            |

### Note


Photographs and graphics are not to scale and do not represent detailed images of the respective products.  
Prices are net prices without VAT and surcharges. Sale to business customers only.

## SKINTOP® CLICK

| Article number             | Article designation / size | Ø F mm      | M (hole in mm) | SW1/SW2 mm  | Overall length C mm | Thread length D mm | Wall thickness, S (mm) | Pieces / PU |
|----------------------------|----------------------------|-------------|----------------|-------------|---------------------|--------------------|------------------------|-------------|
| SKINTOP® CLICK light grey  |                            |             |                |             |                     |                    |                        |             |
| 53112692                   | CLICK 12                   | 4.5 - 7.0   | 12.3 (-0.2)    | 15.0 / 18.0 | 40.0                | 8                  | 1.0 - 4.0              | 50          |
| 53112686                   | CLICK 16                   | 5.0 - 9.0   | 16.3 (-0.2)    | 19.0 / 22.0 | 42.0                | 8                  | 1.0 - 4.0              | 50          |
| 53112687                   | CLICK 20                   | 7.0 - 13.0  | 20.3 (-0.2)    | 25.0 / 27.0 | 45.0                | 8                  | 1.0 - 4.0              | 25          |
| 53112688                   | CLICK 25                   | 9.0 - 17.0  | 25.3 (-0.2)    | 30.0 / 32.0 | 48.0                | 8                  | 1.0 - 4.0              | 25          |
| 53112694                   | CLICK 32                   | 11.0 - 20.0 | 32.3 (-0.2)    | 36.0 / 40.0 | 56.0                | 8                  | 1.0 - 4.0              | 25          |
| SKINTOP® CLICK silver grey |                            |             |                |             |                     |                    |                        |             |
| 53112921                   | CLICK 12                   | 4.5 - 7.0   | 12.3 (-0.2)    | 15.0 / 18.0 | 40.0                | 8                  | 1.0 - 4.0              | 50          |
| 53112876                   | CLICK 16                   | 5.0 - 9.0   | 16.3 (-0.2)    | 19.0 / 22.0 | 42.0                | 8                  | 1.0 - 4.0              | 50          |
| 53112877                   | CLICK 20                   | 7.0 - 13.0  | 20.3 (-0.2)    | 25.0 / 27.0 | 45.0                | 8                  | 1.0 - 4.0              | 25          |
| 53112878                   | CLICK 25                   | 9.0 - 17.0  | 25.3 (-0.2)    | 30.0 / 32.0 | 48.0                | 8                  | 1.0 - 4.0              | 25          |
| 53112922                   | CLICK 32                   | 11.0 - 20.0 | 32.3 (-0.2)    | 36.0 / 40.0 | 56.0                | 8                  | 1.0 - 4.0              | 25          |
| SKINTOP® CLICK black       |                            |             |                |             |                     |                    |                        |             |
| 53112923                   | CLICK 12                   | 4.5 - 7.0   | 12.3 (-0.2)    | 15.0 / 18.0 | 40.0                | 8                  | 1.0 - 4.0              | 50          |
| 53112882                   | CLICK 16                   | 5.0 - 9.0   | 16.3 (-0.2)    | 19.0 / 22.0 | 42.0                | 8                  | 1.0 - 4.0              | 50          |
| 53112883                   | CLICK 20                   | 7.0 - 13.0  | 20.3 (-0.2)    | 25.0 / 27.0 | 45.0                | 8                  | 1.0 - 4.0              | 25          |
| 53112884                   | CLICK 25                   | 9.0 - 17.0  | 25.3 (-0.2)    | 30.0 / 32.0 | 48.0                | 8                  | 1.0 - 4.0              | 25          |
| 53112924                   | CLICK 32                   | 11.0 - 20.0 | 32.3 (-0.2)    | 36.0 / 40.0 | 56.0                | 8                  | 1.0 - 4.0              | 25          |

Last Update (06.06.2023)  
 ©2023 Lapp Group - Technical changes reserved  
 Product Management [www.lappkabel.de](http://www.lappkabel.de)  
 You can find the current technical data in the corresponding data sheet.  
 PN 0456 / 02\_03\_16

# SKINTOP® CLICK

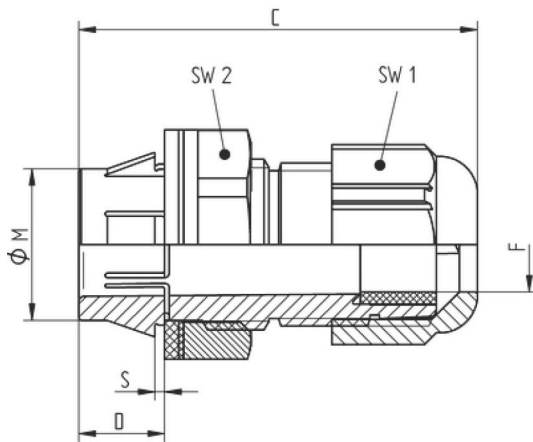

Last Update (06.06.2023)

©2023 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16