


For ¼" x 1" Fuses



Series 3828

Solder Terminals Fuseblock for ¼" x 1" Fuses

(6.4mm x 25.4mm)

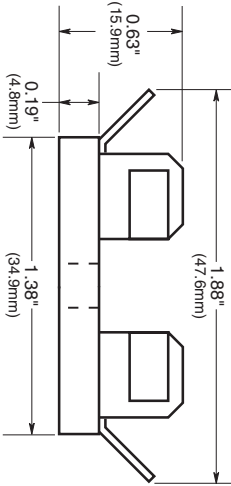


4520 and 4393

Single Pole Fuseblock for ¼" x 1" Fuses


Bakelite base; Width ½" (12.7mm). Spring-bronze, bright tin-lead plated clips. Rated 30A, 250V.

No. 4520—Solder terminals; straight; integral clip and terminal.

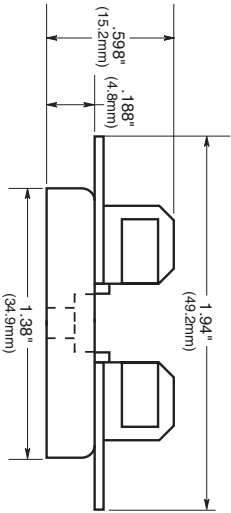

No. 4393—Spare fuseblock.

Note—Mounting screw hole diameter is 0.147" (3.7mm), counterbore 0.636" (8.0mm) diameter. Max. Mounting Screw No. 6.

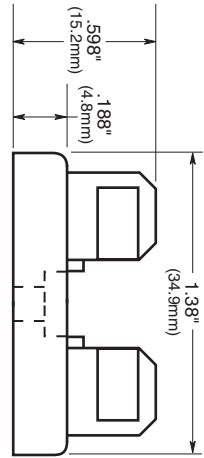

Catalog And Dimensional Data

Catalog Number	No. of Poles	*Base Length	
		inches	mm
3828-1	1	½	12.7
3828-2	2	1¼	28.6
3828-3	3	1¾	44.5
3828-4	4	2¾	60.3
3828-5	5	3	76.2
3828-6	6	3¾	92.1
3828-7	7	4¼	108.0
3828-8	8	4¾	123.8
3828-10	10	6¼	155.6
3828-12	12	7¾	187.3

*Small phenolic base, base width 1½" (34.9mm)

Note—Mounting screw hole diameter is 0.147" (3.7mm) Max. Mounting Screw No. 6.

