


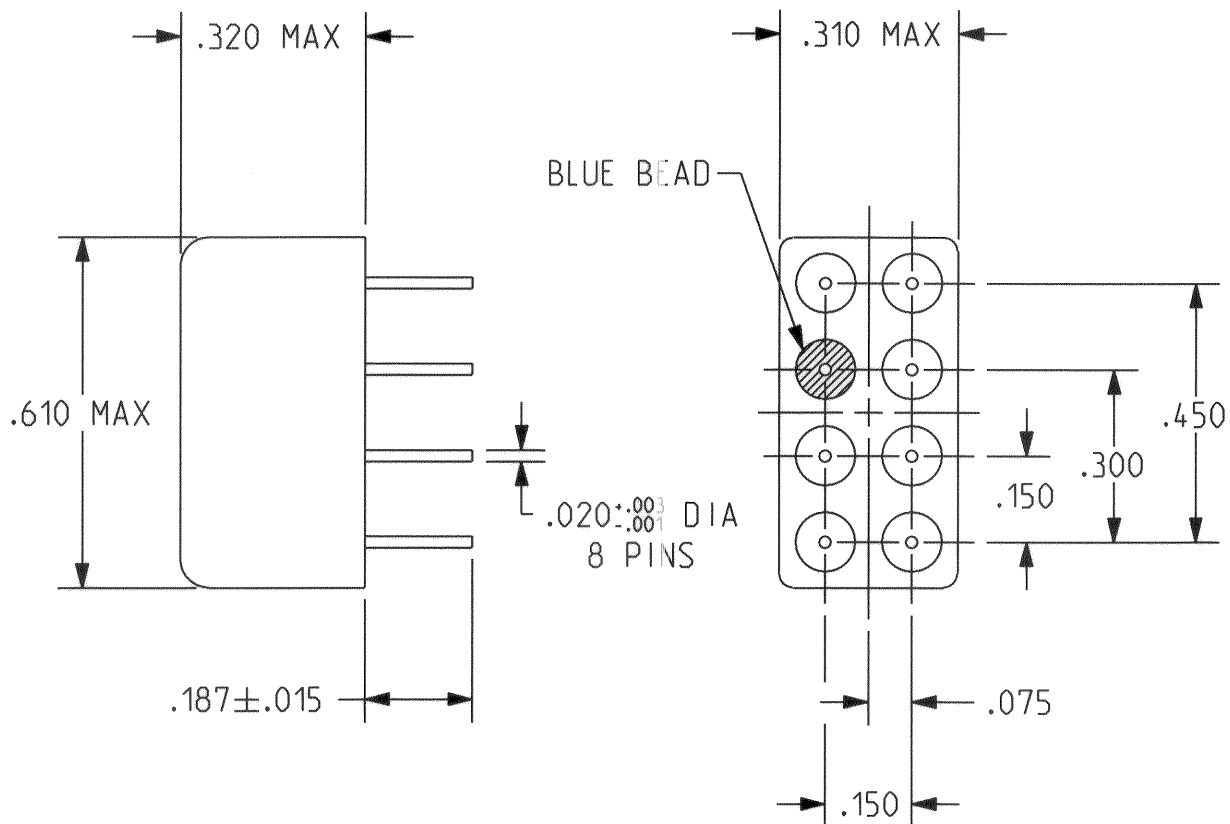

REV. A

DCO 144519

COIL: @ 25°C

RESISTANCE 44 OHMS ±10%

NOMINAL VOLTAGE 5.0 VDC

MUST OPERATE 2.4 VDC

MUST RELEASE 1.45 VDC MAX, 0.26 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 3000 Hz @ 30 g's


SHOCK 75 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.

STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

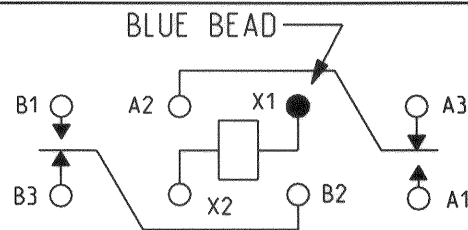

TERMINAL VIEW

CONTACT RATING:

LOW LEVEL TO 2A 28VDC RES.,

100,000 OPS

DR. B.D. 11SEP2008

CK. *[Signature]*

Tyco Electronics

©COPYRIGHT 2005

TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. QPL

CUST. NO. M39016/13-073P REV.

TE NUMBER

2-1617073-1

CII PART NUMBER

3SBC2018A2