

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0428244002

Status:

Active

Description:

3.18mm (.125") Male Pin Terminal

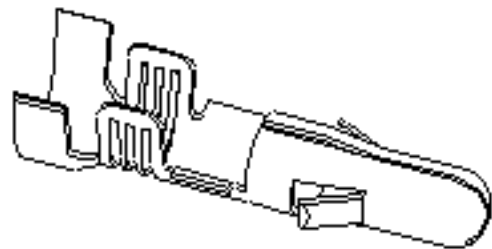


image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-40585 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	42824
Application	Power
Crimp Quality Equipment	Yes
Product Name	N/A
Physical	
Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Packaging Type	Reel
Wire Insulation Diameter	3.94mm-4.45mm (.155-.175")
Wire Size AWG	12
Wire Size mm²	N/A
Electrical	
Current - Maximum per Contact	20A
Voltage - Maximum	600V

Material Info

Reference - Drawing Numbers

Product Specification

PS-40585

Sales Drawing

SD-42824-40**

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
42824Series

Mates With
42825 Male Terminal

Use With
Housing 40585 , 43032

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Terminator	0011402166
Die - 10/18 COMBINATION	
Mini-Mac™ Applicator, 12 AWG and Double Wire	0638321000
12+18 Mini-Mac™ Applicator, 10 AWG,	0638321100

This document was generated on 02/25/2011

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION