


**Extended length is with 500g of force**

### Materials:

- Plug Housing: Polycarbonate, clear
- Plug Terminal: 0.36" [.014MM] Thick Phosphor Bronze
- Connector: 50μ" of Selective Gold Contact Plating
  - Area, Gold flash over the remainder
  - Over 2.54μm [.000100] thick nickel underplate
- Conductor(X4C): 26AWG (0.12X12) Bare Copper
- Insulation(X4C): PP6331 ID 0.95-1.0
- Jacket: PVC NOUL 80P
- Package: Individual PE Bag

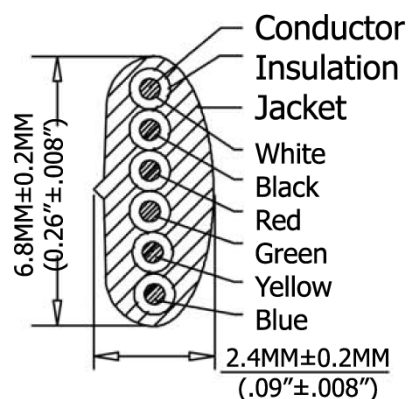

P1	COLOR
1	WHITE
2	BLACK
3	RED
4	GREEN
5	YELLOW
6	BLUE

Extended Length ("L2")	Typical Retracted Length ("L1")
144.0 Inches - 165.6 Inches	51.5 Inches
3,657.6MM-3,505.2MM	1,308.1MM

**SEC: A-A**

**RoHS**  
Compliant

ITEM NO

**AT-C-26-6/6/S-12-OE**

TITLE NON-UL 26AWG (0.16/7)\*6C, O.D.: 2.4\*6.8MM

Single Plug, 50μ" of contact plating, SILVER

**ASSMANN**  
Electronics, Inc.

1840 W. Drake Drive, Suite 101 - Tempe, AZ 85283

Toll Free: 1-877-277-6266 Email: info@usa-assmann.com

THIS DRAWING IS UNPUBLISHED

© Copyright 2009 by Assmann Electronic Components  
All International Rights Reserved