



Products

Customize Your
Parts

Industries
Solutions

Search

News &
Events

First
Time?



Home / Products / Ceres / Standard Size

Product Line

Single Pair Ethernet >

ZConnect >

Ceres >

Accessory

Large Size

Macro Size

Middle Size

Mini Size

Others (GBD)

Others (MAB)

Others (PLD)

Standard Size

X-Lok >

M Series >

FLOS & FLOS+ >

Power >

RBL >

HS-Lok >

NMEA 2000 >

ABOUT AMPHENOL LTW

SUPPORT

PARTNERS

DOWNLOAD CENTER

FEEDBACK

Heavy Duty Shielded >

RJ >

USB >

SSL >

HDMI >

DVI >

Fiber Optic >

RF >


Cable Joiner >

Cable Gland >

Pressure Relief Vent >

LED Light Guide >

D-Sub >

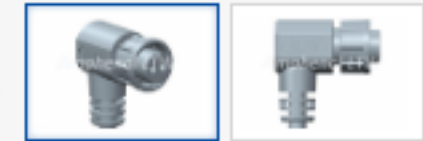

BD-04AFFM-SR7A01

Operating Temperature: -20°C ~ +80°C

Transmission Speed: N/A

Shielded: Plastic, Non-shielded

Jacket Material: PVC

Certificate: N/A

You must login first for view the price

Quantity

- 1 +

Add to Cart

Inquiry



Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type

Search



Ceres. Standard...
1BD-04PMMS-SC7001
-40°C ~ +105°C



Ceres. Standard...
ABD-04PMMS-SC7001
-40°C ~ +105°C



Ceres. Standard...
BD-04PMMM-SL7A01
-20°C ~ +80°C



Ceres. Standard...
BD-04PMMM-SL7A02
-20°C ~ +80°C

Add to Cart

Inquiry

Specifications

Download / CAD

Nominal Current
5A

Connector Type
Overmolded

Shielded
Plastic, Non-shielded

No. of Contacts
04

Connector Gender
Female

Backshell
Right Angle

Mating Style
Screw Thread

IP Rating
IPX7

Assembly Style
N/A

More Options

People Also Bought

