

Specification Sheet

Part Number: MB4A10H4


For use with HellermannTyton T18 - T50 cable ties to provide stability when securing bundles.

4-way opening allows cable ties to be installed parallel or perpendicular to bundles.

The rubber-based adhesive is an economical choice ideal for indoor applications, with a static load weight of 1.1 lb.

Two predrilled holes extend mounting options and solutions.

Extended adhesive liner is easy to remove quickly.

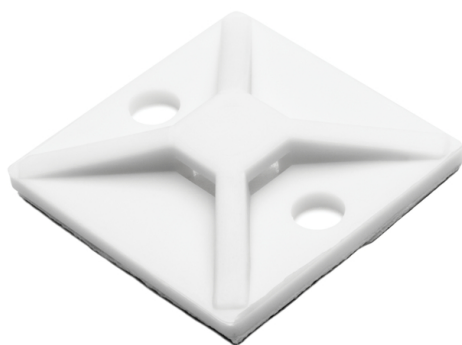

Article Number	151-00321
----------------	-----------

Type	MB4A
------	------

Color	White (WH)
-------	------------

Quantity Per	pack
--------------	------

Product Description	MB4A adhesive mounts are for use with HellermannTyton T18 - T50 Series cable ties to provide stability when securing bundles. The rubber adhesive-backed mounts can be used to secure a bundle and have two predrilled holes to extend mounting options.
---------------------	--

Short Description	Rubber Adhesive Cable Tie Mount, 1.12 x 1.12", Use With T18-T50 Cable Tie, PA66, White, 500/pkg
Global Part Name	MB4A-PA66-WH
Length L (Imperial)	1.12
Length L (Metric)	28.5
Fixation Method	Adhesive
Width W (Imperial)	1.12
Width W (Metric)	28.5
Cable Ties	T18 - T50
Height H (Imperial)	.22
Height H (Metric)	5.6
Cable Tie Width Max (Imperial)	0.18
Cable Tie Width Max (Metric)	4.6
Mounting Hole Diameter D (Imperial)	0.18 "
Mounting Hole Diameter D (Metric)	4.6 mm
Mounting Hole Centers (Imperial)	0.8

Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Adhesive	Synthetic rubber with base of polyethylene foam
Flammability	UL 94 V-2 (excluding adhesive)
UV Resistant (Yes/No)	No
Adhesive Operating Temperature	0°F to +150°F (-18 °C to +66 °C)
Operating Temperature	-40°F to +185°F (-40°C to +85°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	500
Package Quantity (Metric)	500
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#)
[RoHS/WEEE Compliance](#)
[Disclaimer](#)
[Terms and Conditions](#)