
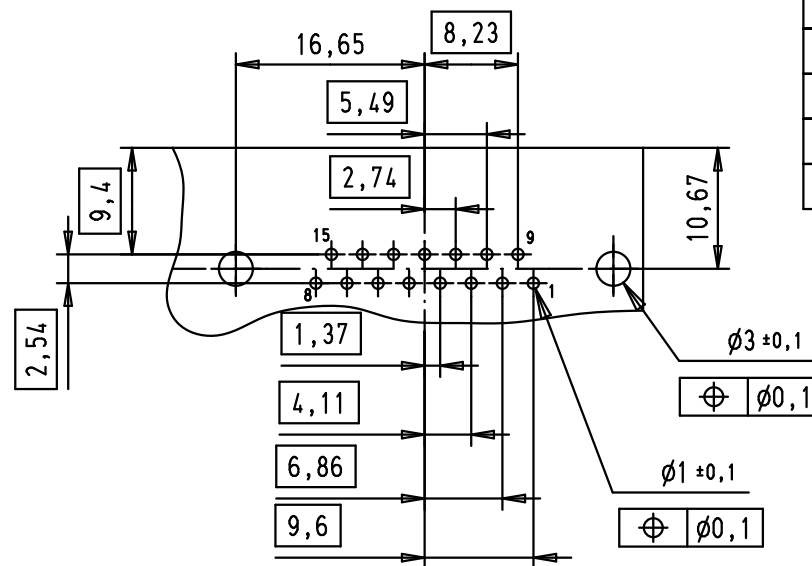


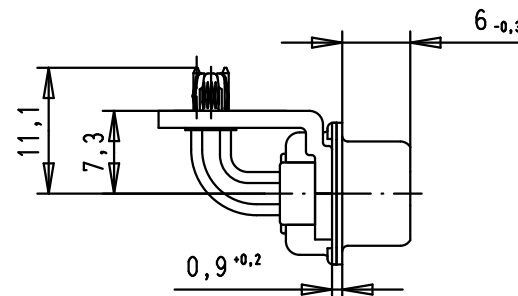

Performance level	PL2
Filter type	C
Capacitance	3900pf±20%
Working Voltage	100v
Current Rating	7.5A
Insulation Resistance	>1GW

FREQUENCY (MHz)	ATTENUATION dB
5	6dB
10	11dB
50	25dB
100	35dB
500	35dB
1000	32dB

							Dat.	Name		D-Sub, male, angled, 15 Poles, turned solder pins, brackets, board-locks and clinch nuts	Mo/Mstab/ Scale 1.5:1
						Detail.	8-JUL-02	CV			
						Insp.	12/01/12	JB			
			36283	12/01/12	SD	Stand.					
09642247243	M3		33271	24/11/05	JMDR	HARTING EURL F-95972 Paris				TB 0964224724x	Blatt/ Pag 1 / 4
09642247242	UNC 4-40		31058	8-JUL-02	CV						
Part number	Nut thread		Mod.	Dat.	Name						