


YS39, Cu Compression Splice, 750 kcmil

By Burndy
Catalog # YS39

750 kcmil, CU, Long Barrel SPLICE

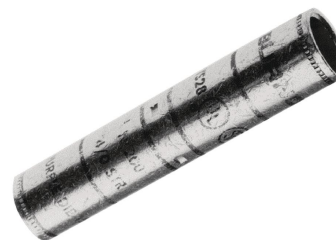

Features

- Copper seamless barrel with center stop indentations to indicate when wire is fully inserted into each side of the barrel
- Electro-tin plated unless otherwise specified to reduce galvanic corrosion (bimetallic) and resist corrosive elements
- Connectors clearly marked with color coding

Application

Wire Splice

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	BABA Compliant (All status valid till December 2026)
Industry Standard(s)	UL 486A-486B
Certification - ETL	No
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Material	COPPER
Wire Size	750 kcmil
Conductor - Copper Str Size	750 kcmil
Conductor Size	750 KCMIL
Conductor Type	CODE
Conductor - Copper Str Size Range	750 kcmil

Configuration

Connector Type	LONG BARREL
----------------	-------------

Current

Voltage Rating	35 kV
Voltage - Maximum	35000

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	162 mm
Dimension - Strip Length inch	2-7/8
Dimension - B Length inch	2.81 in
Dimension - Length Overall inch	6.38 in

General

Trade Name	HYLINK™
Die Index	24
Feature - Barrel Type	Long
Feature - Barrel Style	Chamfered
Plated	Y
Color Code	Black
Sub Brand	HYLINK
UPC	781810526859
Type	YS, Long Barrel
Material	Copper
Plating Type	Tin - Electro Plated
Finish Type	Tin-Plated
UPC 12 Digit	781810526859
UPC 14 Digit GTIN	00781810526859

Logistics

Minimum Pack Quantity	1
Carton Quantity	6

Product Assets

[Catalog \[English\]](#)