


Part Number : 1300940420

Product Description : Standard Duty Support Grip, Offset Eye, Split Rod, Single Weave, Cable Diameter 50.80-63.25mm (2.000-2.490"), Approximate Break Strength 1524.07kg (3360 lbs)

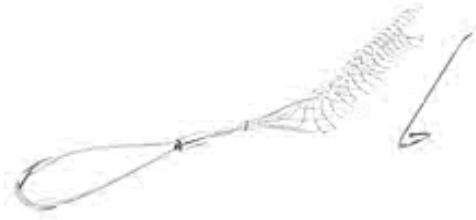

Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Number : 35307

Documents & Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not saleable
China RoHS	Not saleable
EU ELV	Not saleable
Low-Halogen Status	Not saleable
REACH SVHC	Not saleable
EU RoHS	Not saleable

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Standard Duty Support Grip, Offset Eye, Split Rod, Single Weave, Cable Diameter 50.80-63.25mm (2.000-2.490"), Approximate Break Strength 1524.07kg (3360 lbs)
Product Name	Standard Duty
Type	Support Grip
UPC	78678835307

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	1524.07kg (3360 lbs)
Bale Length	0.152m (6.00")
Body Style	Straight
Cable Diameter	50.80-63.25mm (2.000-2.490")
Color - Grommet	N/A
Eye Type	Offset
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.559m (22.00")
Net Weight	1.000/g
Number of Holes	N/A
O-Ring	N/A
Thread Size	N/A

This document was generated on Sep 22, 2025