


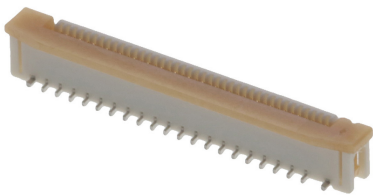

Part Number : [525594052](#)
Product Description : Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 40 Circuits, Gold Plating
Series Number : 52559
Status : Active
Product Category : FFC / FPC Connectors



Documents & Resources

Drawings

[Drawing 525594052_sd.pdf](#)

3D Models and Design Files

- [2D Drawing DXF 525594052.dxf](#)
- [2D Drawing DXF \(PDF\) 525594052.pdf](#)
- [3D Model 525594052_stp.zip](#)

Specifications

- [Application Specification AS-52559-001-001.pdf](#)
- [Packaging Specification SPK-52559-003-001.pdf](#)
- [Product Specification PS-52559-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	FFC / FPC Connectors
Series	52559
Description	Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 40 Circuits, Gold Plating
Product Family	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	822348533732

Agency

UL	E29179
----	--------

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

Physical

Actuator Type	Slider
Circuits (Loaded)	40
Contact Position	N/A
Durability (mating cycles max)	20
Flammability	94V-0
Mated Height	3.90mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold

Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	468.662/mg
Number of Rows	1
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Pitch - Mating Interface	0.50mm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

Mates With / Use With

Mates with Part(s)

Description	Part Number
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15020</u>
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15120</u>

This document was generated on Oct 22, 2023