


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:	0734040190
Status:	Active
Overview:	SMB RF Connectors
Description:	75 Ohms, SMB Jack, PCB Air Dielectric

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

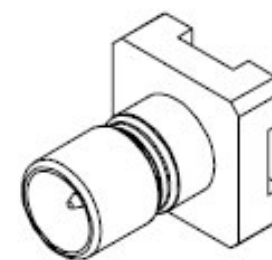

Series image - Reference only

General

Product Family	RF/Coax Connectors
Series	<u>73404</u>
Overview	<u>SMB RF Connectors</u>
Product Name	SMB
Style	PCB
Type	Subminiature
UPC	822350066747
Wire/Cable Type	N/A

Physical

Gender	Jack
Keying to Mating Part	None
Net Weight	0.610/g
Orientation	Straight
PCB Mounting	Surface Mount
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
Reverse Polar	No

Electrical

Frequency	4 GHz
Impedance	75Ω
Power / Voltage	VOLTAGE: 335 Vrms@Sea Level

Solder Process Data

Duration at Max. Process Temperature (seconds)	005
Lead-free Process Capability	REFLOW
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	260

Material Info

Reference - Drawing Numbers

Sales Drawing SD-73404-019-001

EU ELV

Not Relevant

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2021)10043-DC (17
Jan 2022)
Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

73404 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION