

SEK CAB FLAT SH RND AWG28/7 25P 100m

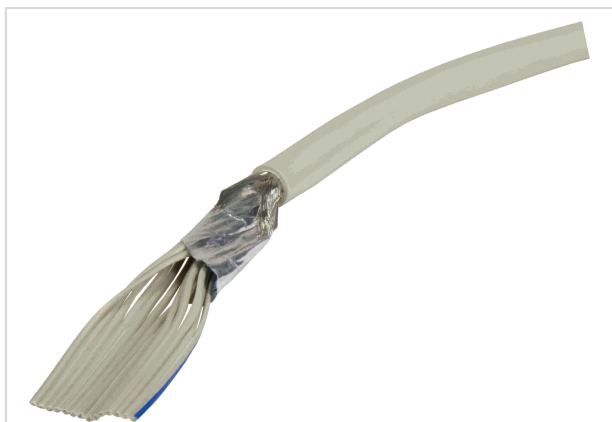


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 025 7010
Specification	SEK CAB FLAT SH RND AWG28/7 25P 100m
HARTING eCatalogue	https://b2b.harting.com/09180257010

Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (round)

Version

Cable length	100 m
Shielding	Shielded
Number of cores	25
Core structure	AWG 28/7

Technical characteristics

Impedance	100 Ω
Limiting temperature	-30 ... +75 °C unmoved -20 ... +75 °C moved
Conductor resistance @ 20 °C	$\leq 216 \Omega/\text{km}$

Material properties

Material (cable)	PVC
Colour (cable)	Grey
RoHS	compliant
ELV status	compliant
China RoHS	e



Pushing Performance

Material properties

REACH Annex XVII substances	No
-----------------------------	----

REACH ANNEX XIV substances	No
----------------------------	----

REACH SVHC substances	No
-----------------------	----

Specifications and approvals

Specifications	UL 1581 Sec. 1061 UL PLCC, CL2
----------------	-----------------------------------

CE	Yes
----	-----

Commercial data

Packaging size	1
----------------	---

Country of origin	USA
-------------------	-----

European customs tariff number	85444993
--------------------------------	----------

eCl@ss	27061801 Data and communication cable (copper)
--------	--