

## Han EE 18 Pos. Insert Female Crimp

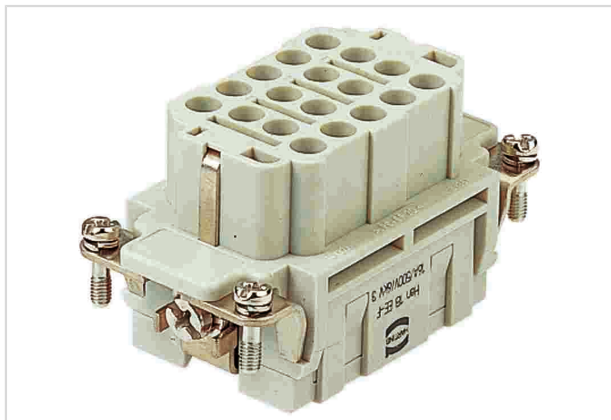


Image is for illustration purposes only. Please refer to product description.

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| Part number        | 09 32 018 3101                                                                        |
| Specification      | Han EE 18 Pos. Insert Female Crimp                                                    |
| HARTING eCatalogue | <a href="https://b2b.harting.com/09320183101">https://b2b.harting.com/09320183101</a> |

### Identification

|          |                     |
|----------|---------------------|
| Category | Inserts             |
| Series   | Han <sup>®</sup> EE |

### Version

|                    |                                         |
|--------------------|-----------------------------------------|
| Termination method | Crimp termination                       |
| Gender             | Female                                  |
| Size               | 10 B                                    |
| Number of contacts | 18                                      |
| PE contact         | Yes                                     |
| Details            | Please order crimp contacts separately. |

### Technical characteristics

|                           |                            |
|---------------------------|----------------------------|
| Conductor cross-section   | 0.14 ... 4 mm <sup>2</sup> |
| Conductor cross-section   | AWG 26 ... AWG 12          |
| Rated current             | 16 A                       |
| Rated voltage             | 500 V                      |
| Rated impulse voltage     | 6 kV                       |
| Pollution degree          | 3                          |
| Rated voltage acc. to UL  | 600 V                      |
| Rated voltage acc. to CSA | 600 V                      |
| Insulation resistance     | >10 <sup>10</sup> Ω        |
| Limiting temperature      | -40 ... +125 °C            |



Pushing Performance

## Technical characteristics

|               |      |
|---------------|------|
| Mating cycles | ≥500 |
|---------------|------|

## Material properties

|                                           |                        |
|-------------------------------------------|------------------------|
| Material (insert)                         | Polycarbonate (PC)     |
| Colour (insert)                           | RAL 7032 (pebble grey) |
| Material flammability class acc. to UL 94 | V-0                    |
| RoHS                                      | compliant              |
| ELV status                                | compliant              |
| China RoHS                                | e                      |
| REACH Annex XVII substances               | No                     |
| REACH ANNEX XIV substances                | No                     |
| REACH SVHC substances                     | No                     |

## Specifications and approvals

|                |                                                                                     |
|----------------|-------------------------------------------------------------------------------------|
| Specifications | EN 60664-1<br>IEC 61984                                                             |
| Approvals      | DNV GL                                                                              |
| UL / CSA       | UL 1977 ECBT2.E235076<br>UL 2237 PVVA2.E318390<br>CSA-C22.2 No. 182.3 PVVA8.E318390 |

## Commercial data

|                                |                                                   |
|--------------------------------|---------------------------------------------------|
| Packaging size                 | 1                                                 |
| Net weight                     | 55 g                                              |
| Country of origin              | Romania                                           |
| European customs tariff number | 85366990                                          |
| eCl@ss                         | 27440205 Contact insert for industrial connectors |