




Part Number : [150200833](#)

Product Description : 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 30.00mm Cable Length, Gold (Au) Plating, 15 Circuits

Series Number : 15020

Status : Active

Product Category : Flat-Flexible Cable (FFC)

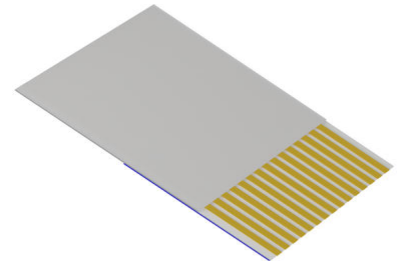

Documents and Resources

Drawings

[150200833_sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[PS-15020-001-001.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

[Industry Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15020
Description	0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 30.00mm Cable Length, Gold (Au) Plating, 15 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex FFC Jumper
UPC	884982181083

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Physical

Cable Length	30.00mm
Circuits (Loaded)	15
Contact Layout Type	A (same side)
Design Feature	Flexible
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 15 Circuits, Phosphor Bronze, Gold Plating	<u>5019511530</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 15 Circuits, Copper Alloy, 125°C Operating Temperature, Gold Plating	<u>5019511550</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 15 Circuits, Gold over Nickel Plating	<u>5051101592</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 15 Circuits, Gold Plating	<u>525591552</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 15 Circuits, Gold Plating	<u>527451597</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 15 Circuits, Gold Plating	<u>527461571</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.20mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 15 Circuits, Gold (Au) Plating	<u>545481572</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Standard	<u>781191520</u>

Footprint, Gold Plating, Black, 15 Circuits	
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Gold Plating, Black, 15 Circuits	<u>781271520</u>

This document was generated on Dec 31, 2025