



19" frame (Novastar), Heavy-Duty, RAL 7021, 25 U x 553 mm x 800 mm

SCHROFF

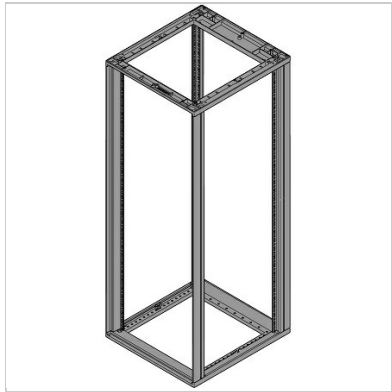

Configuration

Other Views

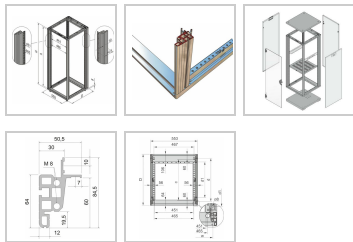

Catalog Number: 28230-439

Back To Product

- 19" plane - 60mm at front, 60 mm at rear
- Al profile, RAL 7021, incl. GND/earthing
- Static load-carrying capacity 400 kg

Product family:

Novastar

Note:

Please order doors, rear panels, side panels, top cover assemblies, plinths, floors, shelves, slide rails and castors or adjustable feet separately

Accessory category:

Frame



Select product specifications before modifying or adding to project list or requesting a quote.

Height-U-mm-defining

25 U / 1167 mm ▾

Depth-mm-defining

800 ▾

[Clear Selection](#)

Quantity

Modify Product ▶

Add Item to Project List +

Documents



Main Catalog - Novastar

Links



Native CAD files

Technical Data

Depth mm	800.0
Height mm	1167.0
Width mm	553.0
Qty	1 piece
Color	RAL 7021
Description	static load-carrying capacity: 400 kg, Al extrusion, RAL 7021, incl. GND/earthing; 19" plane 60 mm at front, 60 mm at rear; please order castors or adjustable feet separately

Delivery Comprises:

Item	Quantity	Description
1	2	Frame, at bottom and top, Al extrusion; screwed down with uprights
2	4	Uprights with 19" perforation, Al extrusion
3	1	Earthing kit

Accessories

EXPLORE	CONTACT	DOWNLOAD
About Us	Customer Service	Download Center
Services & Capabilities	Find a Sales Office or Distributor	Reference Projects
News & Events	Global Locations	Videos
Newsletter Subscriptions	Product Compliance & Certifications	Product Configurators
Strategic Partnerships	Partner Login	Warranties and Terms of Sale & Procurement
Investor Relations		

© 2018 nVent. All rights reserved | [Privacy Policy](#) | [Terms of Use](#) | [Cookie Policy](#) | [Imprint](#) | [Site Map](#)

Connect With Us

