


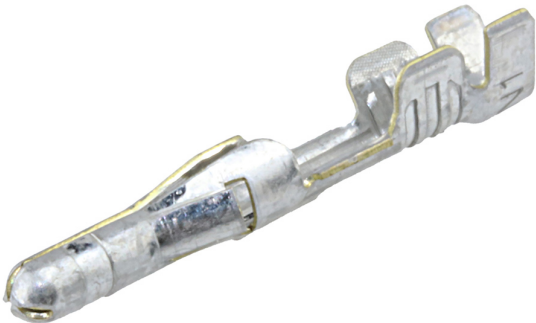

Part Number : 02092118
Product Description : 2.36mm Diameter,
Standard .093" Pin and Socket Crimp
Terminal, Series 1380, Male, with Tin (Sn)
Plated Brass Contact, 22-18 AWG, Bag
Series Number : 1380
Status : Active
Product Category : Crimp Terminals
Engineering Number : 1380-(P901)L
Packaging Alternative : 02092116 (Reel)




Documents & Resources

Drawings
[002092118_sd.pdf](#)
[PK-1190-003-001.pdf](#)

Specifications
[PS-02-09-001.pdf](#)
[11890000-TS-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Crimp Terminals
Series	1380
Description	2.36mm Diameter, Standard .093" Pin and Socket Crimp Terminal, Series 1380, Male, with Tin (Sn) Plated Brass Contact, 22-18 AWG, Bag
Application	Power, Wire-to-Wire
Product Name	Standard .093"
UPC	800753746114

Physical

Durability (mating cycles max)	25
Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.206/g
Packaging Type	Bag
Plating min - Mating	0.508µm
Plating min - Termination	0.508µm
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	1.52-3.05mm
Wire Size (AWG)	18, 20, 22
Wire Size mm ²	N/A

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Use with Part(s)

Description	Part Number
Standard .093" Pin and Socket Dual Row Connector Housings	<u>1261</u>
Standard .093" Pin and Socket 3 Row Connector Housings	<u>1292</u>
Standard .093" Pin and Socket Single Row Connector Housings	<u>1396</u>
Standard .093" Pin and Socket Single Row Connector Housings	<u>1490</u>
Standard .093" Pin and Socket Single Row Connector Housings	<u>1545</u>
Standard .093" Pin and Socket Single Row Connector Housings	<u>1619</u>

Application Tooling

Global

Description	Part Number
Insertion Tool for Standard .093" Pin and Socket Terminals	<u>11020003</u>
Extraction Tool for Standard .093" Pin and Socket Terminals	<u>11030006</u>
Extractor Tool for .093 and HCS-125 Product Series	<u>638240200</u>
Hand Crimp Tool for Standard .093" Pin and Socket Crimp Terminals, 18 AWG	<u>638280900</u>
Hand Crimp Tool for .093" Pin and Socket Crimp Terminals, 22 AWG	<u>638281400</u>
Hand Crimp Tool for Standard .093" Pin and Socket Crimp Terminals, 20 AWG	<u>638281700</u>

This document was generated on Mar 18, 2025